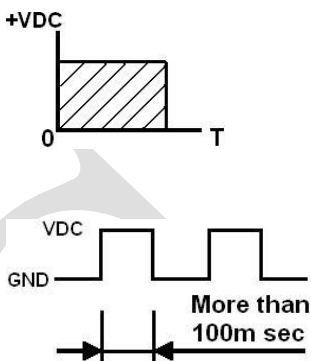


## 1. SPECIFICATION

AX-1005-P15

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	4 ~ 7	
03	Mean consumption Current	mA Max.	30	
04	Resonant Frequency	Hz	3100± 300	
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A)	Min.85	Rated Voltage, Distance at 10cm

REV NO.

REVISION NOTE

APPROVAL

DATE

PRINT

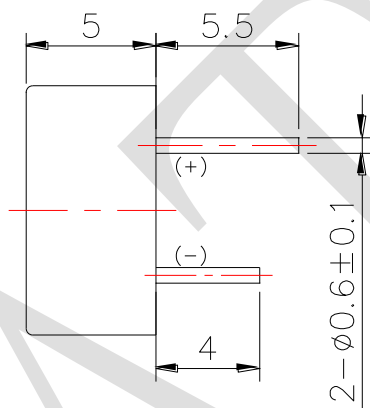
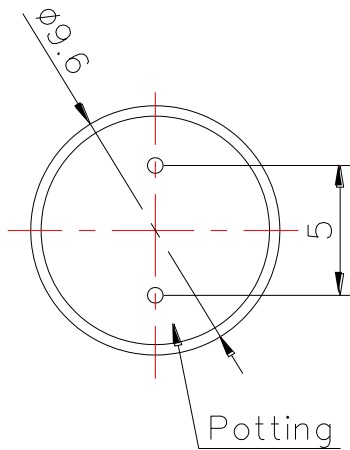
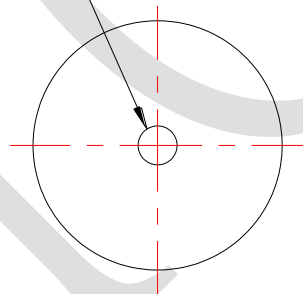
AX-1005-P15



AX-1005-P15



(+)

SOUND PORT  $\phi 1.5$ 

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Moose 2015/10/07

SCALE: 4:1 SHEET: 1 of 1

PART NO. AX-1005-P15

DESIGNED: R&amp;D OF AAT

UNITS: mm

DWG NO. FDB-096050F-05031

2

CHECKED:

TOLERANCE  $\pm 0.5$ 

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: PPO

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-1005-P15](#)