
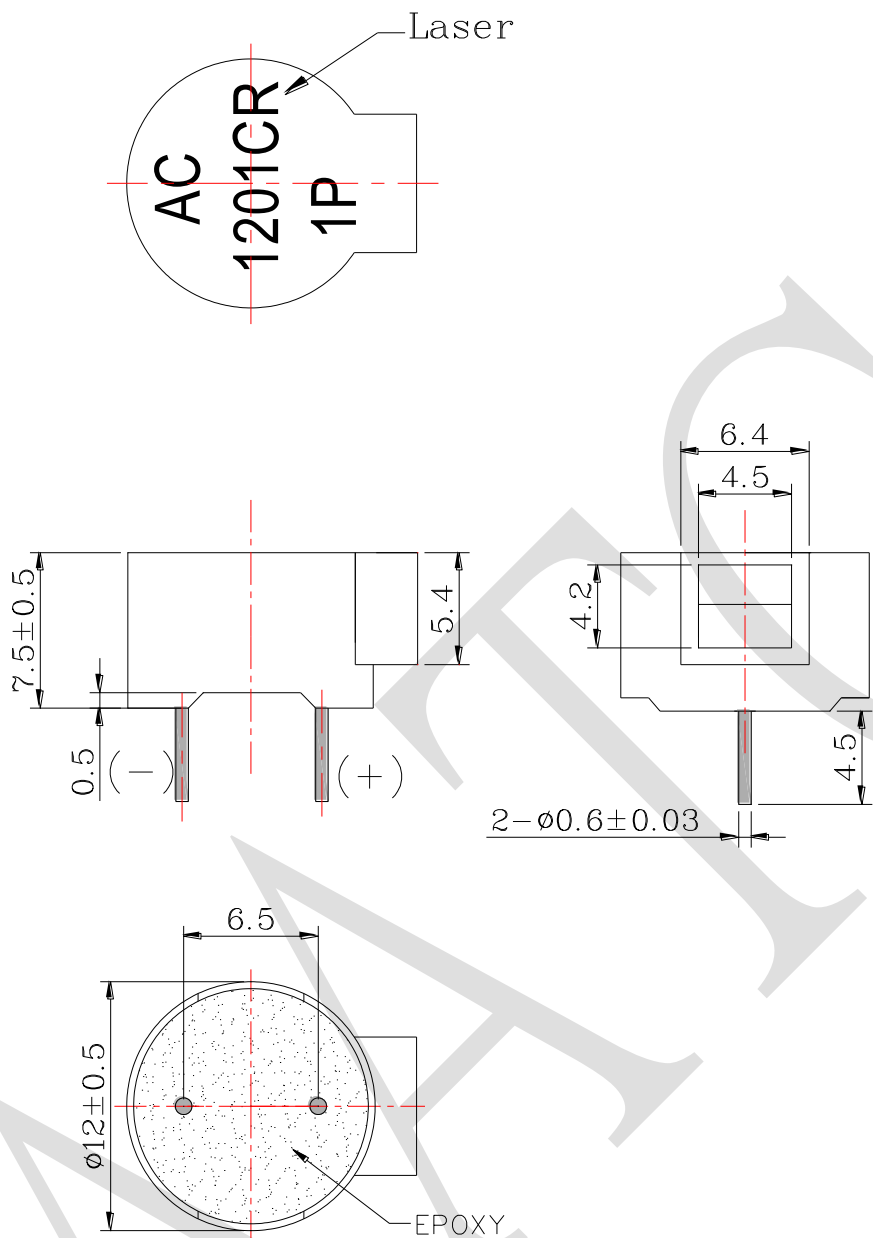


# 1. SPECIFICATION

AC-1201-CR-1P

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.2	 <p>Standard state, standard drive circuit. Square wave 1/2 duty.</p>
02	Operating Voltage	V	1 ~ 3	
03	Consumption Current	mA Max.	70	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	88	Rated voltage, rated frequency.
05	Direct Current Resistance	$\Omega$	6 $\pm$ 1	
06	Rated Frequency	Hz	2731	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Moose	2016/12/22	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-1201-CR-1P		DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. UGCM0401BP4.5DR6		CHECKED:		TOLERANCE $\pm 0.5$	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: NORYL		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1201-CR-1P](#)