 



1. SPECIFICATION

AC-1001N-RP3

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	 Standard state, standard drive circuit. Square wave 1/2 duty.
02	Operating Voltage	V	1 ~ 2	
03	Consumption Current	mA Max.	80	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	90	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	5.5±1	
06	Rated Frequency	Hz	2950	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

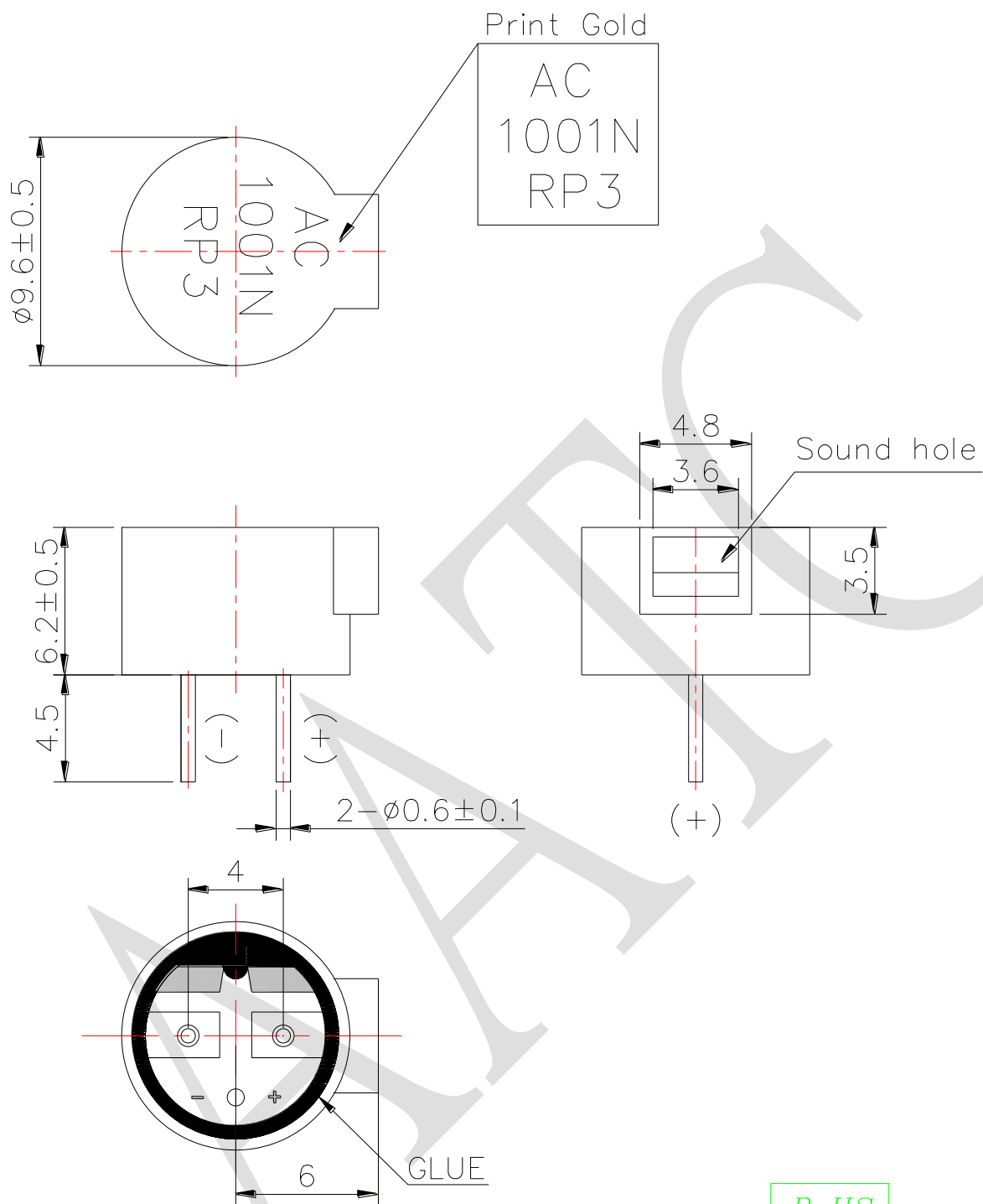

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Zack	2018/07/25	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-1001N-RP3	1	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. JM96621G5-P		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL ± *** TWO PLACE DECIMAL ± *** THREE PLACE DECIMAL ± ***	
	REV	MATERIAL: PPO			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AC-1001N-RP3