


1. SPECIFICATION

AZ-1438E-1PV



ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	<div><p>Square wave 1/2 duty.</p></div>
02	Operating Voltage	V	1~ 30	
03	Consumption Current	mA (Max)	1	
04	Sound pressure level (Distance at 10cm )	dB(A) (Min)	75	Rated voltage, rated frequency.
05	Capacitance	pF	13000±30%	At 120 Hz
06	Rated Frequency	Hz	3800	Rated Voltage

REV NO.

REVISION NOTE

APPROVAL


DATE

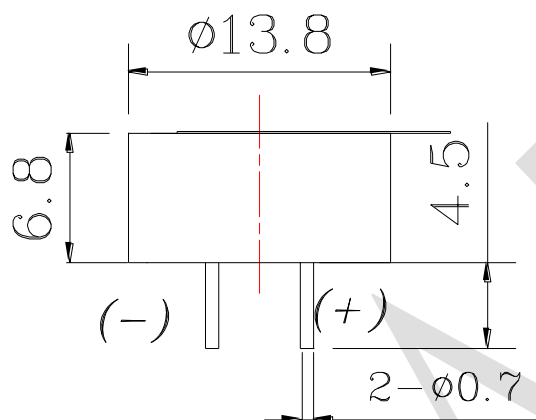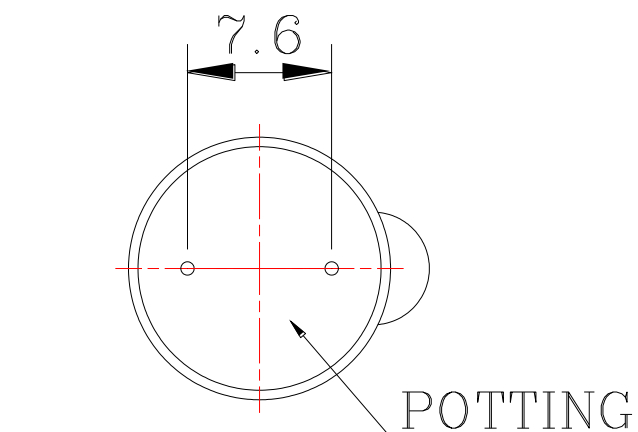

PRINT:Silver

 AZ-1438E  
 -1PV ⊕

(+)

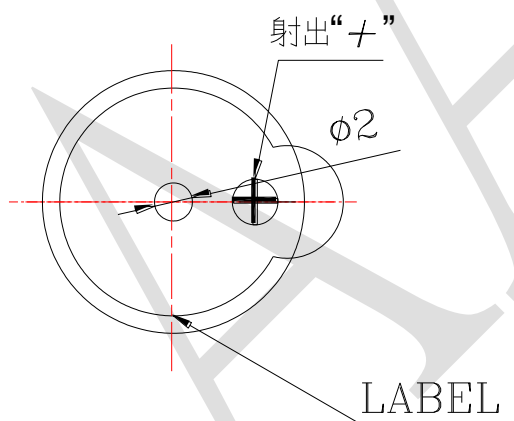

RoHS

TITLE: PIEZO BUZZER

DRAWN: Moose 2015/11/17

SCALE: 2:1

SHEET: 1:1

PART NO. AZ-1438E-1PV

DESIGNED: R&amp;D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. UGPM14A3805P

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± \*\*\*

TWO PLACE DECIMAL ± \*\*\*

THREE PLACE DECIMAL ± \*\*\*

MATERIAL: NORYL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-1438E-1PV