 

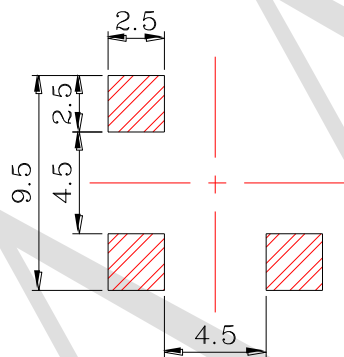


1. SPECIFICATION

AD-8504-CQ14

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.6	
02	Operating Voltage	V	3 ~ 5	
03	Consumption Current	mA (Max)	Mean : 100	Standard state, standard drive circuit. Rated voltage, rated frequency, Square wave 1/2 duty.
			Peak : 300	
04	Sound pressure level (Distance at 10cm)	dB(A) (Min)	82	
05	Direct Current Resistance	Ω	16±3	
06	Rated Frequency	Hz	2730	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

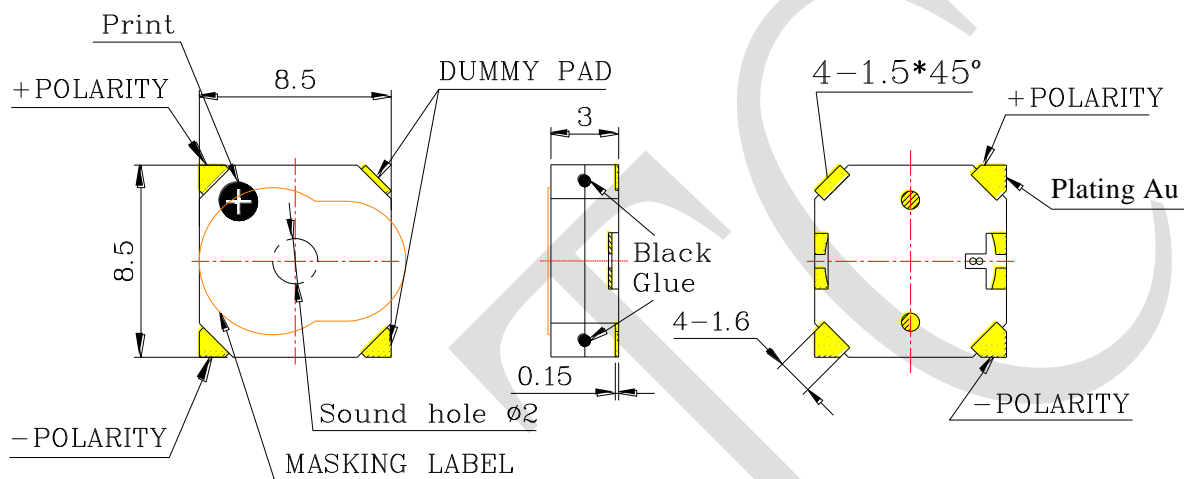

RECOMMEND P.C.B LAYOUT

RoHS

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: Jerry	2013/05/23	SCALE: 1:1	SHEET: 1 : 1
PART NO. AD-8504-CQ14	1	DESIGNED: R & D OF AAT	UNITS: mm		
DWG NO. JTG8503A16		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
	REV	MATERIAL: LCP	ONE PLACE DECIMAL \pm ***		
			TWO PLACE DECIMAL \pm ***		
			THREE PLACE DECIMAL \pm ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AD-8504-CQ14](#)