


# 1. SPECIFICATION

AC-1205D-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5.0	
02	Operating Voltage	V	3.0 ~ 8.0	
03	Consumption Current	mA (Max)	Mean : 50	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 150	
04	Direct Current Resistance	$\Omega$	45±6	
05	Sound pressure level (Distance at 10cm )	dBA (Min)	85	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2400	

REV NO.

REVISION NOTE

APPROVAL



DATE

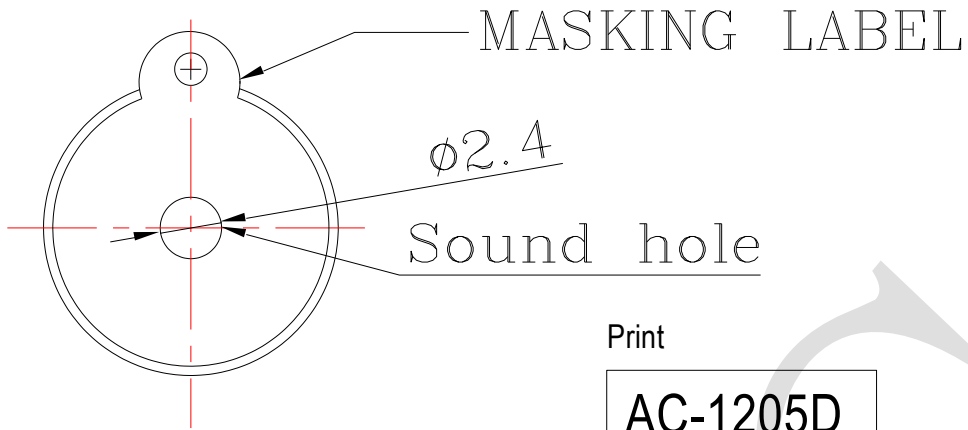

Print

AC-1205D  
-LF  $\oplus$

AC-1205D  
-LF  $\oplus$

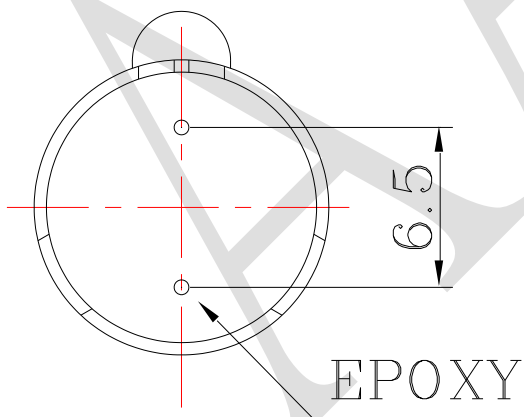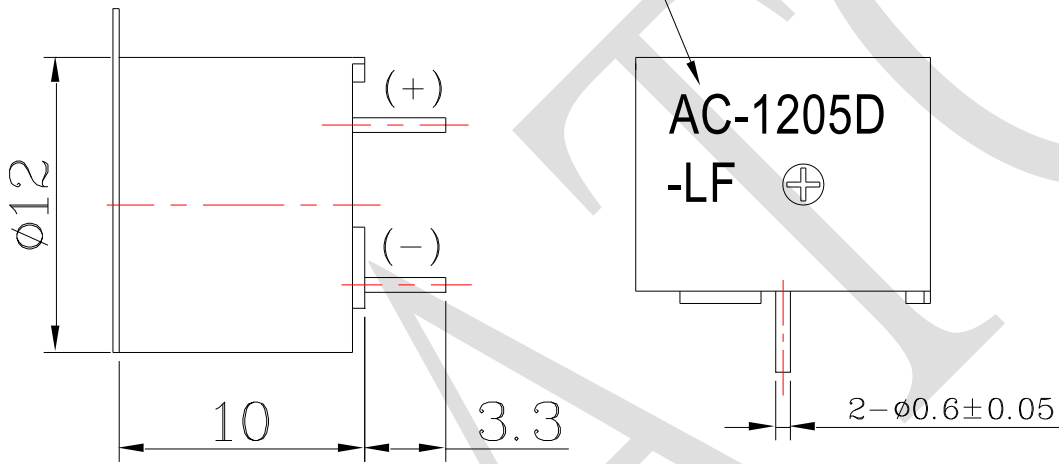

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Jerry 2013/01/18

SCALE: 4:1 SHEET: 1 of 1

PART NO. AC-1205D-LF

DESIGNED: R&D OF AAT

UNITS: mm

2

CHECKED:

TOLERANCE  $\pm 0.5$

DWG NO. UGC12G-05PB-45

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

REV

MATERIAL: PBT

ONE PLACE DECIMAL  $\pm$  \*\*\*

TWO PLACE DECIMAL  $\pm$  \*\*\*

THREE PLACE DECIMAL  $\pm$  \*\*\*



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1205D-LF](#)