 



1. SPECIFICATION


AC-7E3D

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	 Standard state, standard drive circuit. Square wave 1/2 duty.
02	Operating Voltage	V	2 ~ 4	
03	Consumption Current	mA Max.	150	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	70	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	8 ± 1	
06	Rated Frequency	Hz	3100	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

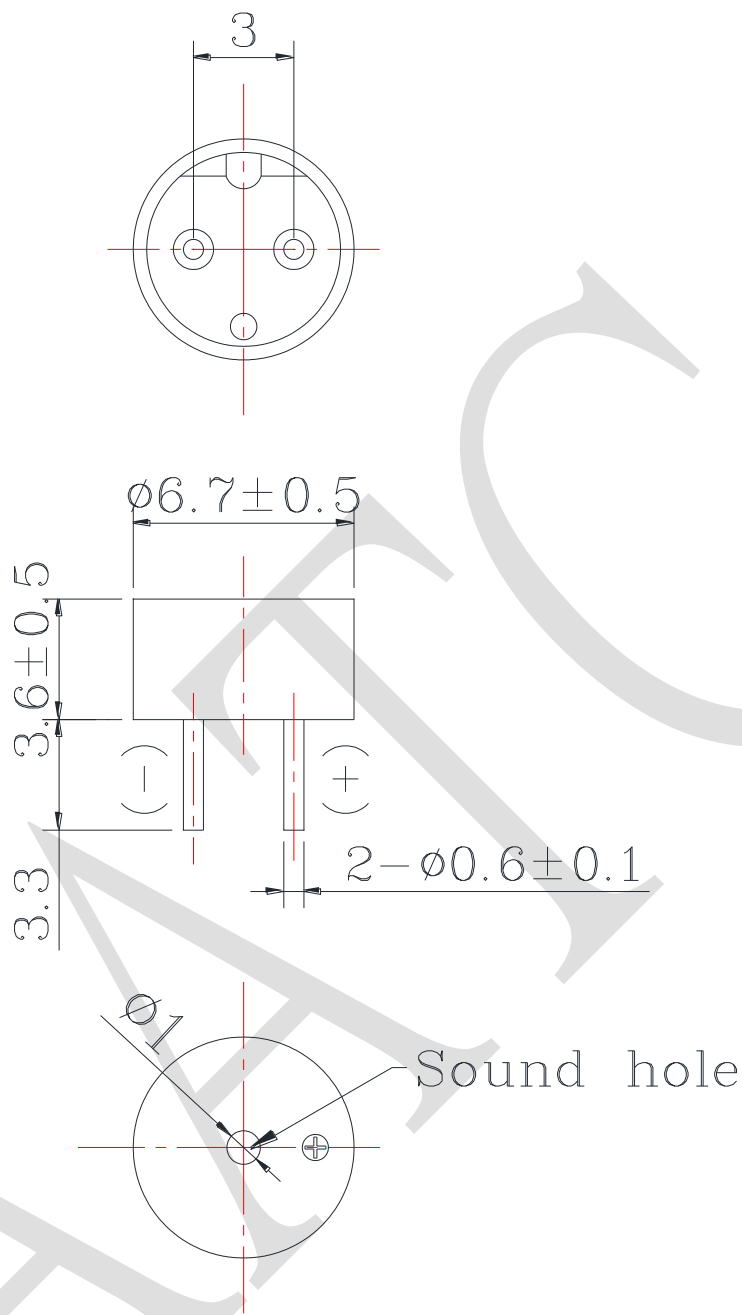

RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Zack	2020/04/16	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-7E3D	1	DESIGNED:	R&D OF AAT	UNITS:	mm
		CHECKED:		TOLERANCE	$\pm 0.5$
		APPROVAL:		FIRST ANGLE PROJECTION	
DWG NO. **** _ *****	REV	MATERIAL:	NORYL		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)  
[AC-7E3D](#)