 



1. SPECIFICATION

AC-701R-P1-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	 Standard state, standard drive circuit. Square wave 1/2 duty.
02	Operating Voltage	V	1.0 ~ 3.0	
03	Consumption Current	mA Max.	210	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	65	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	8±1	
06	Rated Frequency	Hz	3100	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

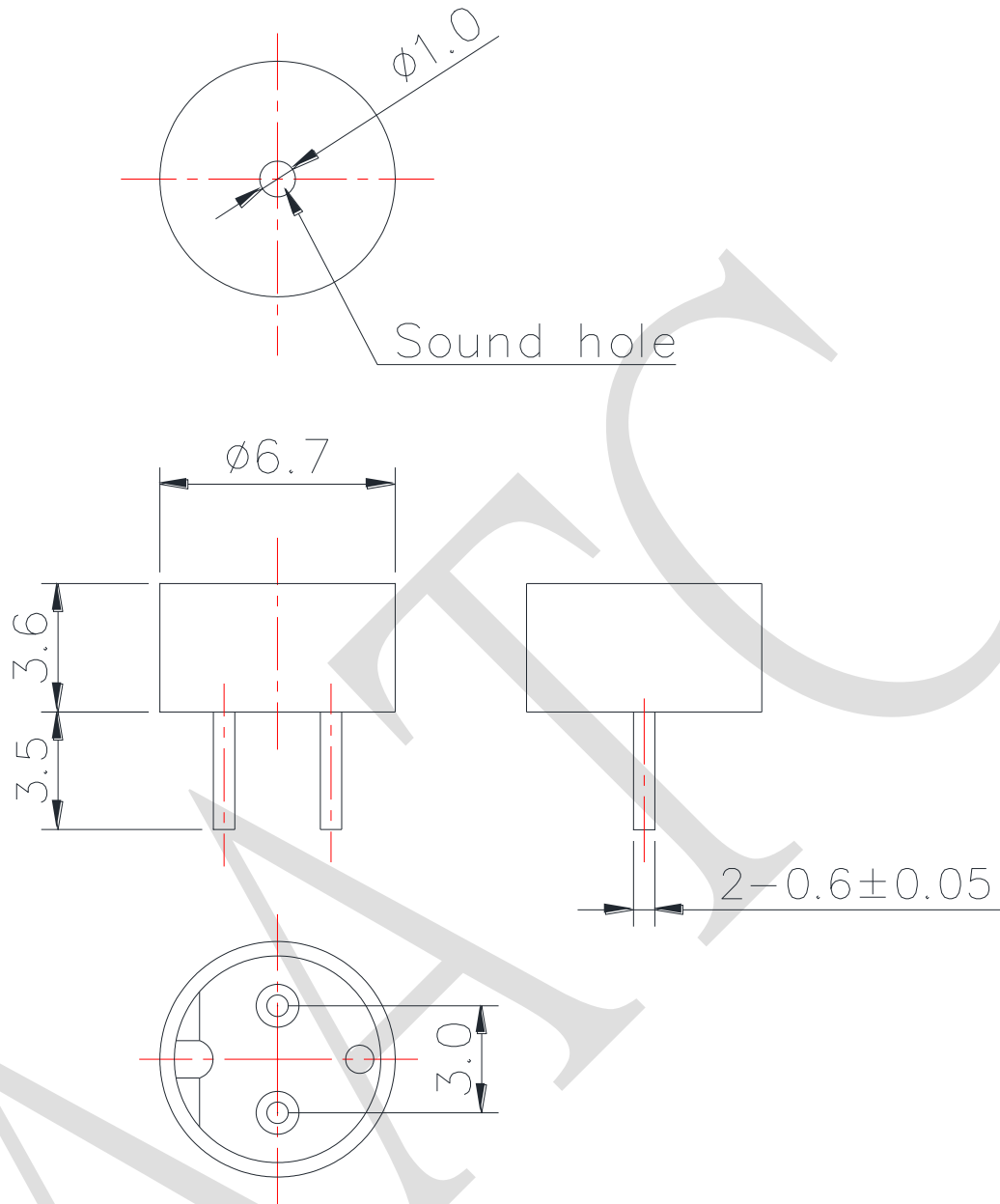

RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Hank	2019/10/05	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-701R-P1-LF	3	DESIGNED:	R&D OF AAT	UNITS:	mm
DWG NO. UGCM0601APE-65		CHECKED:		TOLERANCE	± 0.5
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL:	NORYL	ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-701R-P1-LF](#)