
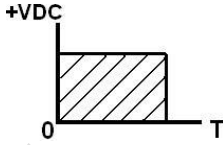


1. SPECIFICATION

AZI-3029S-1C-HF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	18	
02	Operating Voltage	V	15~ 25	
03	Consumption Current	mA(Max)	20	
04	Resonant Frequency	Hz	2900± 500	
05	Sound pressure level (Distance at 10cm )	dBA(Min)	100	Rated Voltage Resonant Frequency

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

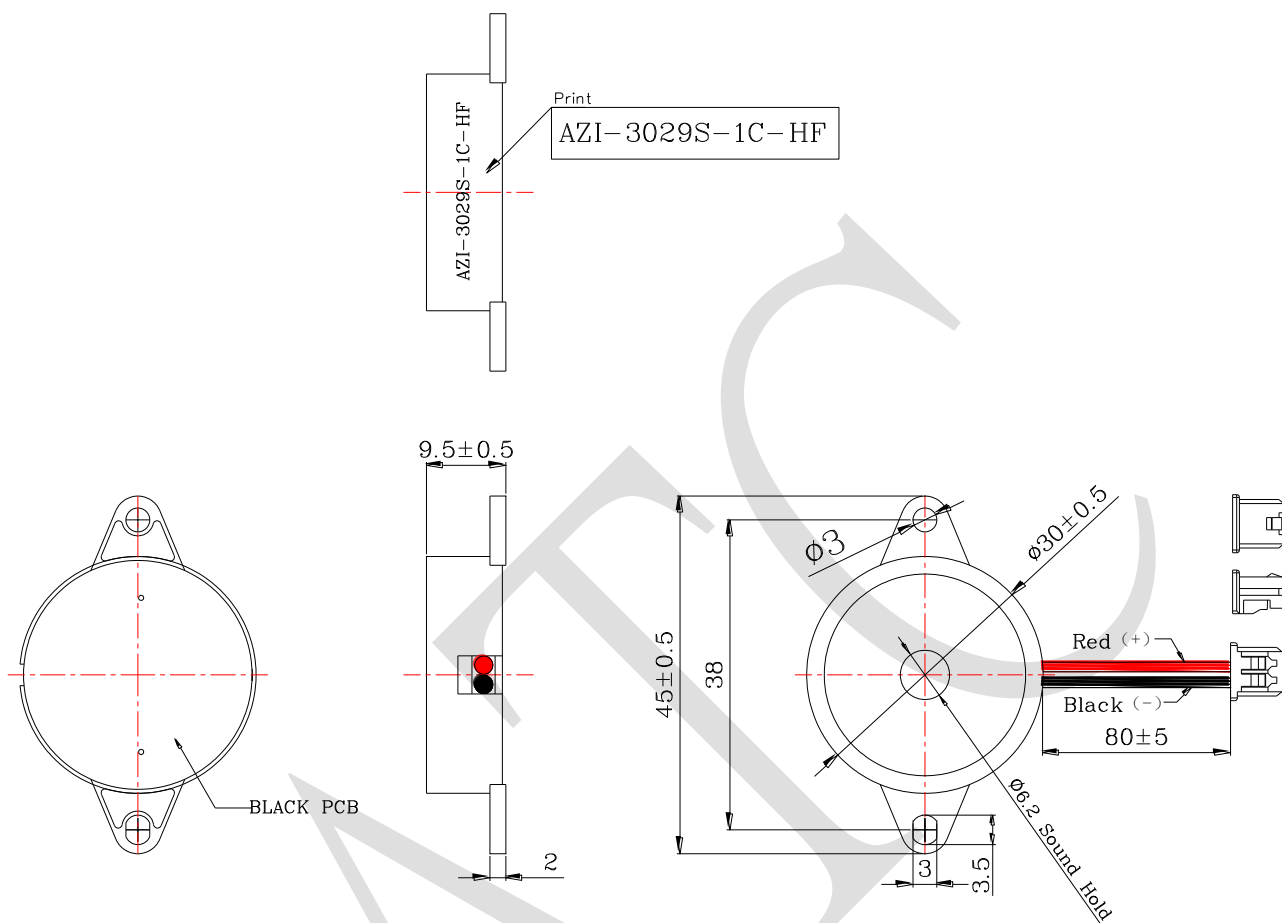

Wire: UL3302 AWG28#

Connector: Equivalent to Molex 51021-0200

HF

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <b>Moose</b> 2017/05/11	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>AZI-3029S-1C-HF</i>	3	DESIGNED: AATC R&D	UNITS: mm	
		CHECKED:	TOLERANCE $\pm 0.3$	
DWG NO. <i>BPC3095WC80-1829</i>	REV	APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: PPO	ONE PLACE DECIMAL $\pm$ ***	
		TWO PLACE DECIMAL $\pm$ ***		
		THREE PLACE DECIMAL $\pm$ ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AZI-3029S-1C-HF](#)