

1. SPECIFICATION

AZ-4228S-W5


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	4 ~ 20	
03	Rated Current	mA(Max)	9	Rated Voltage
04	Sound pressure level (Distance at 30cm)	dBA(Min)	96	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	2800	Rated Voltage
06	Resonant Frequency	Hz	2800 ± 500	

REV NO.

REVISION NOTE

APPROVAL

DATE

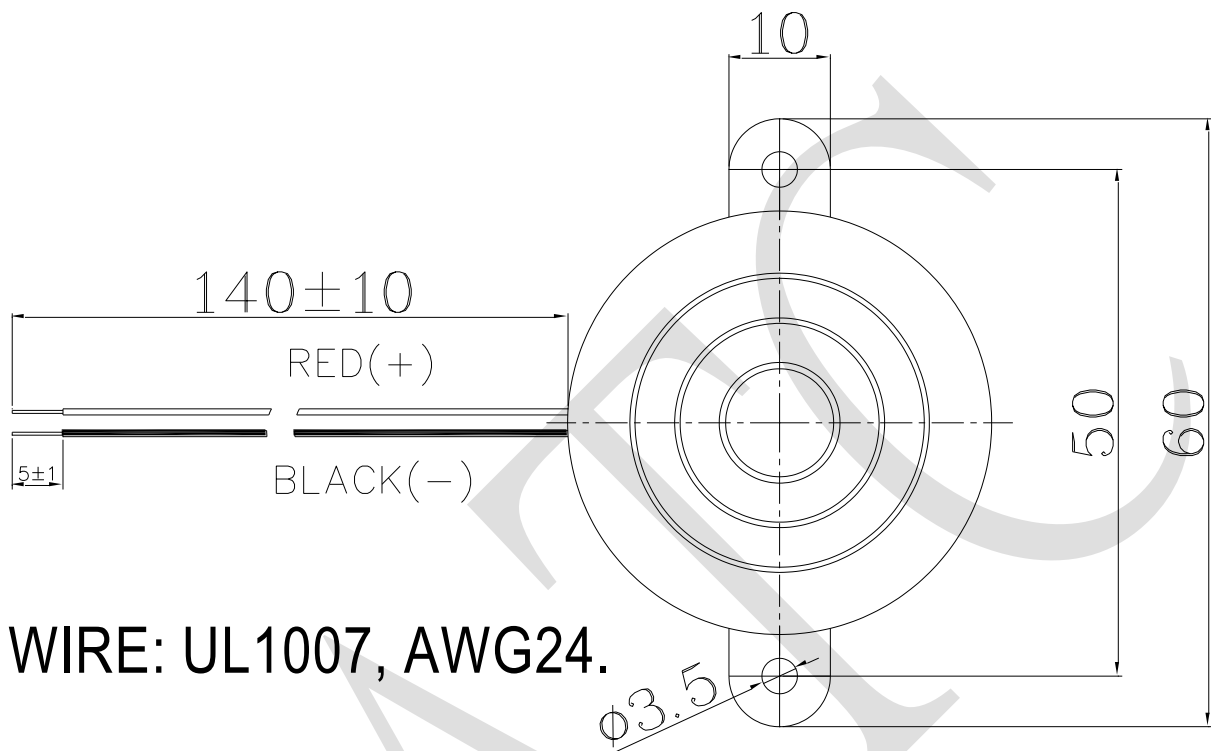

WIRE: UL1007, AWG24.

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Zack	2012/8/15	SCALE: 2:1	SHEET: 1 of 1
PART NO. <i>AZ-4228S-W5</i>	2	DESIGNED: <i>R & D OF AAT</i>		UNITS: <i>mm</i>	
DWG NO. <i>DTP-1030</i>		CHECKED:		TOLERANCE ± 0.3	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL \pm *** TWO PLACE DECIMAL \pm *** THREE PLACE DECIMAL \pm ***	
	REV	MATERIAL: <i>ABS</i>			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-4228S-W5