

1. SPECIFICATION

AZ-1640E-WV8-1


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	1~ 30	
03	Rated Current	mA(Max)	7	Rated Voltage
04	Sound pressure level (Distance at 10cm )	dBA(Min)	80	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4000± 300	Rated Voltage
06	Capacitance	pF	15000±30%	At 120Hz

REV NO.



REVISION NOTE

APPROVAL

DATE

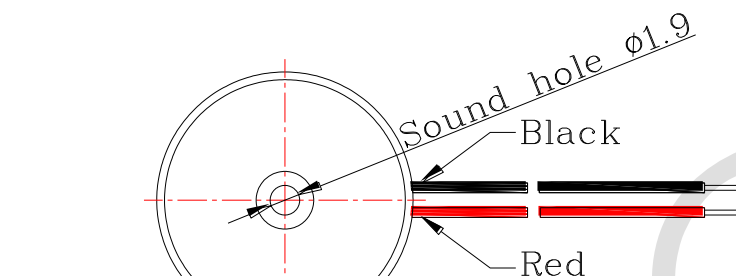

Wire: UL 1571.AWG30#

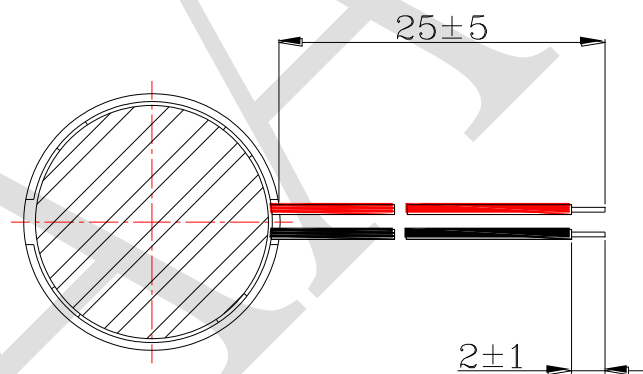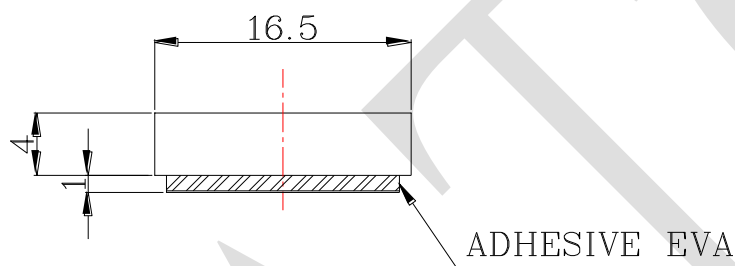

RoHS

TITLE: PIEZO BUZZER

DRAWN: Zack 2015/10/05

SCALE: 2:1

SHEET: 1:1

PART NO. AZ-1640E-WV8-1

DESIGNED: R&amp;D OF AAT

UNITS: mm

CHECKED:

TOLERANCE  $\pm 0.5$ 

DWG NO. UGPA17A4009W25T-1

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

REV

MATERIAL: MPP0



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-1640E-WV8-LF