

1. SPECIFICATION

AZ-2455E-W1




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	15	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	1~ 30	
03	Rated Current	mA(Max)	8	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	90	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	5500± 300	Rated Voltage
06	Capacitance	pF	18000±30%	At120Hz

REV NO.

REVISION NOTE

APPROVAL

DATE

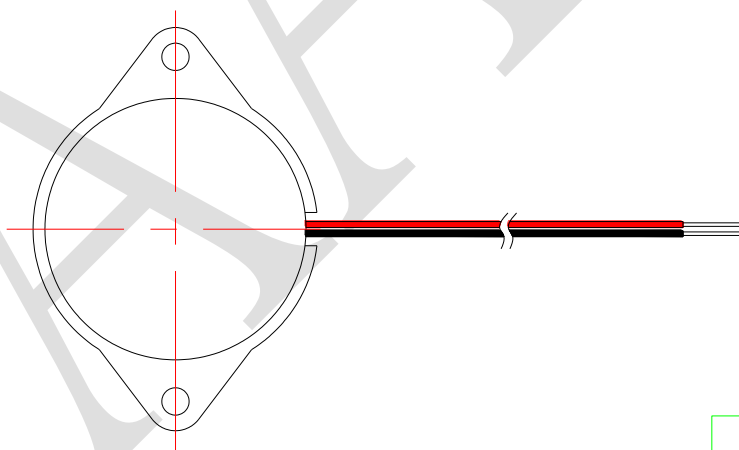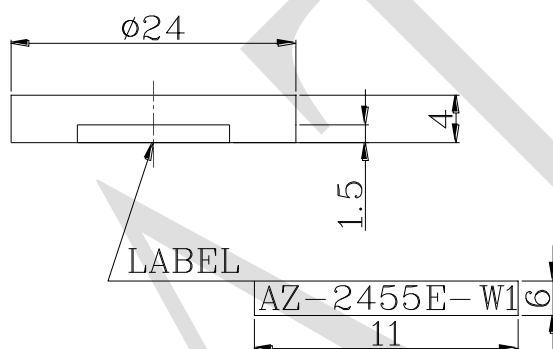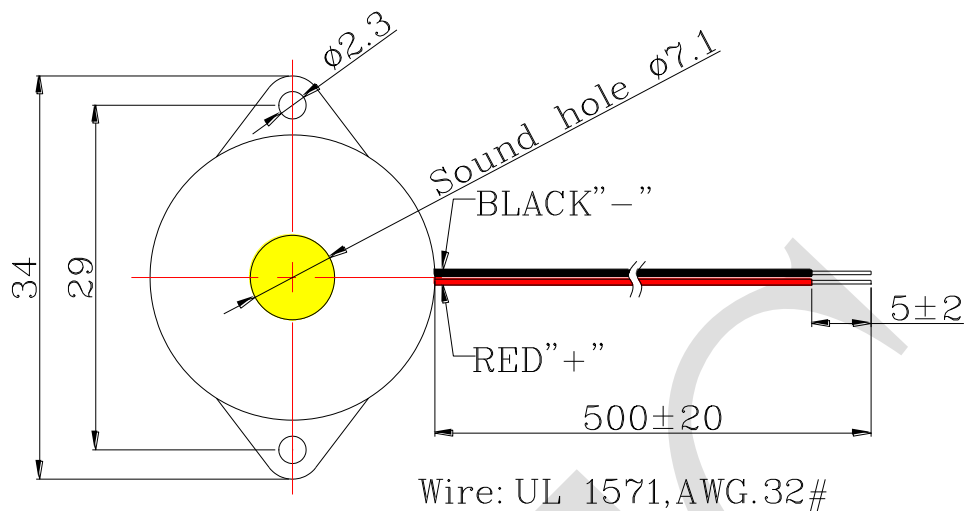

RoHS

TITLE: PIEZO BUZZER

DRAWN: Jerry 2013/10/09

SCALE: 2:1

SHEET: 1:1

PART NO. AZ-2455E-W1

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. UGPA24C5515W500

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

MATERIAL: MPPO



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-2455E-W1](#)