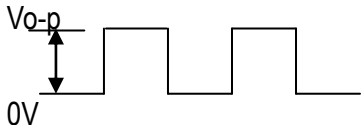


## 1. Specifications

AC-1212H-F





Items		Units	Specifications	Conditions
01	Rated Voltage	Vo-p	12	
02	Operating Voltage	Vo-p	6~16	
03	Consumption Current	mA (Max)	Mean 80	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak 240	
04	Direct Current Resistance	Ohm	140±21	
05	Sound Output	dBA (min)	85	Applying rated voltage, rated frequency square wave, Distance at 10cm 1/2duty subject to standard state.
06	Rated Frequency	Hz	2400	

REV NO.

REVISION NOTE

APPROVAL

DATE

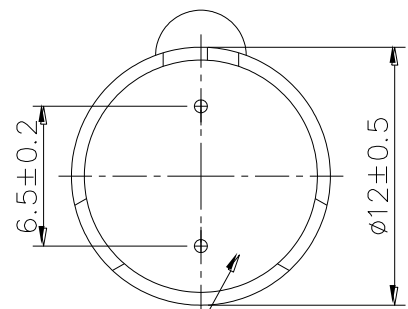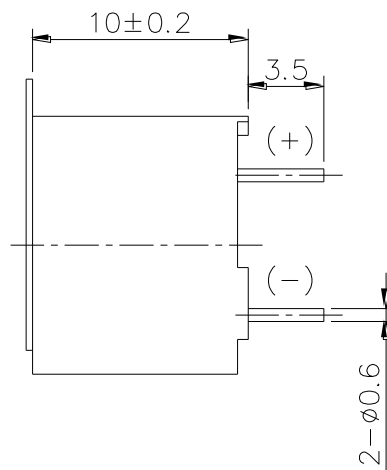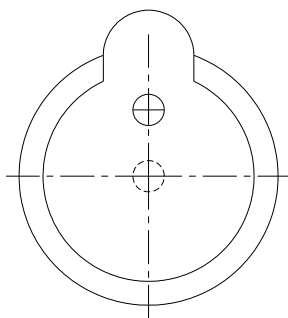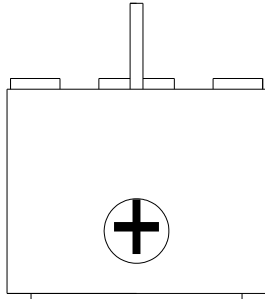

EPOXY POTTING

TITLE: SOUND TRANSDUCER

DRAWN: Jack

2003/07/22

SCALE: 3:1

SHEET: 1 of 1

PART NO. AC-1212H-F

1

DESIGNED: R&amp;D OF AAT

UNITS: mm

DWG NO. DTE-1050

REV

CHECKED:

APPROVAL:

MATERIAL: NORYL

TOLERANCE ± 0.5

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± \*\*\*

TWO PLACE DECIMAL ± \*\*\*

THREE PLACE DECIMAL ± \*\*\*



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1212H-F](#)