
 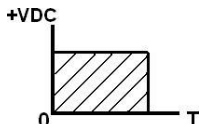



1. SPECIFICATION

AD-1305-GVS

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	4 ~ 7	
03	Consumption Current	mA (Max)	30	Rated Voltage
04	Resonant Frequency	Hz	2400 ± 300	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	90	Distance at 10cm Rated Voltage / Resonant Frequency

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

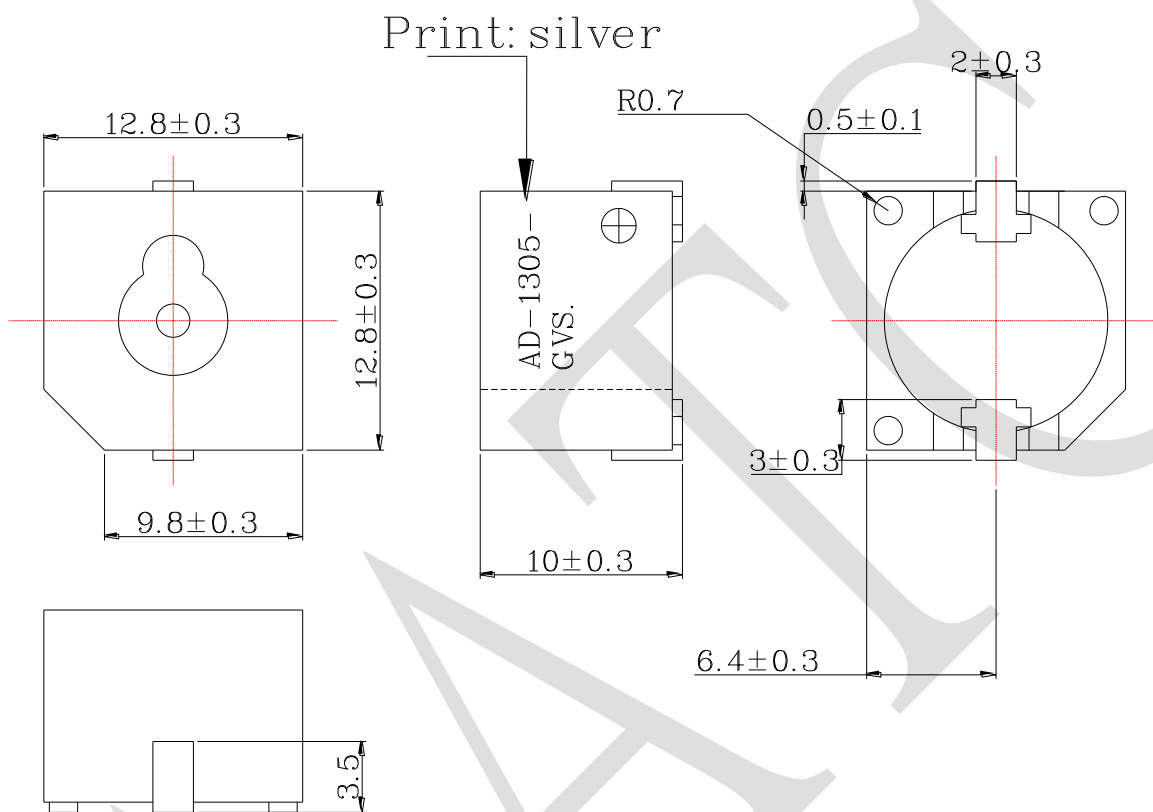

RoHS

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: Zack	2018-02-21	SCALE: 1:1	SHEET: 1 : 1
PART NO. AD-1305-GVS		DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. FDM-1773 SMD-128100F-05024B		CHECKED:		TOLERANCE ± 0.5	
REV		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: PPS		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AD-1305-GVS](#)