


1. SPECIFICATIONS

AMF-O60F25-1FWH3

01	Electret's Type	Foil type
02	Sensitivity	-25±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	2.0 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	20 – 16 K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
10	S/N Ratio	≥60dB
11	Sound Pressure Level	110 dB

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

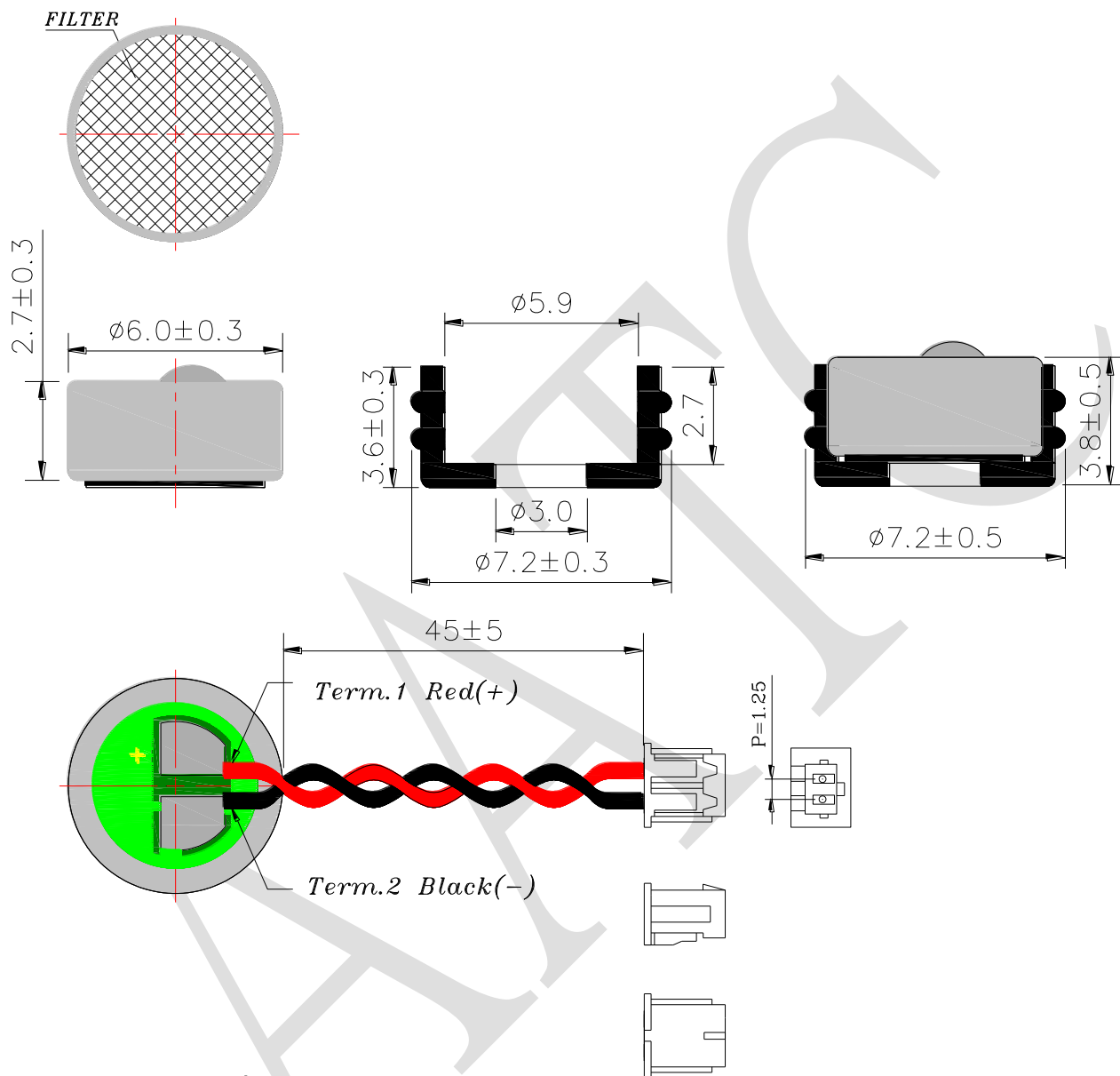

Wire : UL1571,AWG32#
Holder : DD-EQ-JTC72-05
Connector : Equivalent to Molex 51021-0200

RoHS

TITLE: MICROPHONE		DRAWN: Jack	2016/12/09	SCALE: 5:1	SHEET: 1 of 1
PART NO. AMF-060F25-1FWH3		DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. *****		CHECKED:		TOLERANCE ± 0.3	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: AL		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AMF-O60F25-1FWH3](#)