 


## 1. SPECIFICATION

AC-1201E-RP

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	
02	Operating Voltage	V	1 ~ 3	
03	Consumption Current	mA (Max)	Mean : 70	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 210	
04	Direct Current Resistance	$\Omega$	6.5 $\pm$ 1	
05	Sound pressure level (Distance at 10cm )	dBA (Min)	88	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2730	

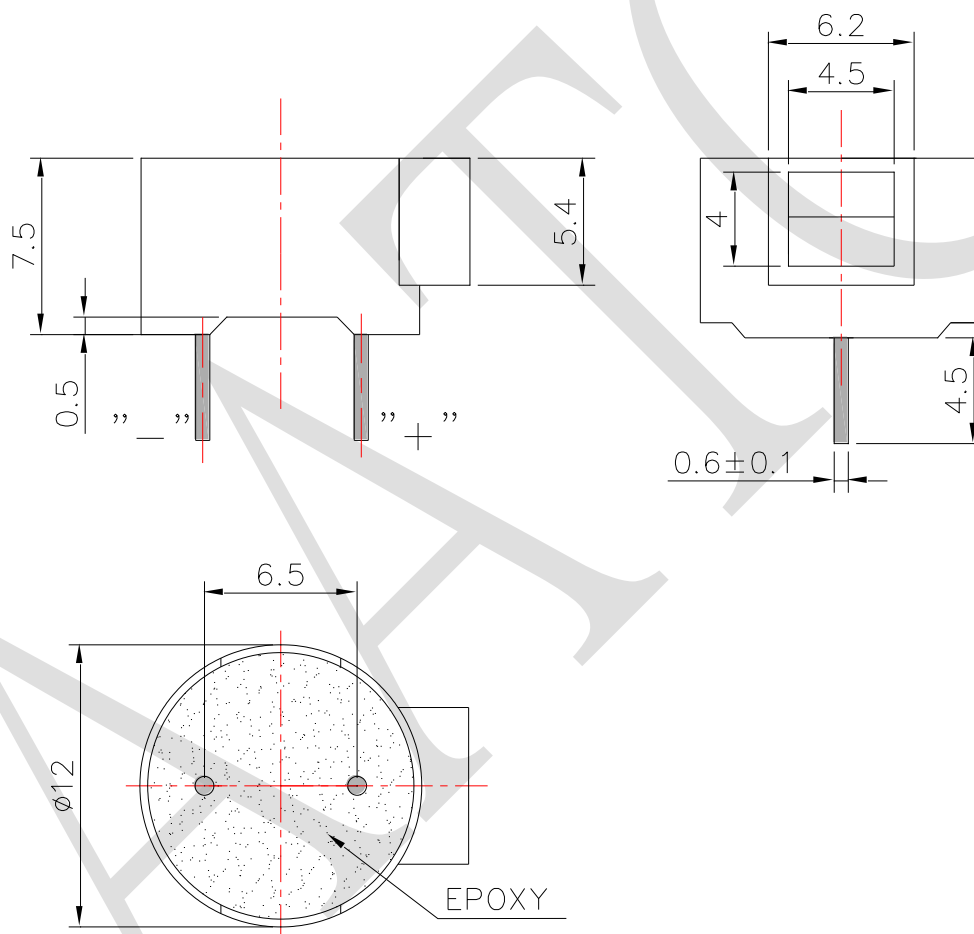
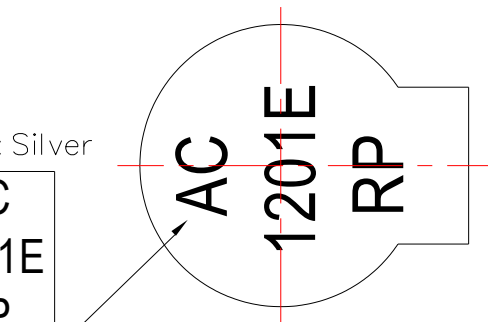
REV NO.

REVISION NOTE

APPROVAL

DATE

Print: Silver

AC  
1201E  
RP

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: **Zack** 2012/08/15

SCALE: 4:1 SHEET: 1 of 1

PART NO. AC-1201E-RP

DESIGNED: R&amp;D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. HS-110601

APPROVAL:

UNLESS OTHERWISE SPECIFIED:  
ONE PLACE DECIMAL ± \*\*\*

2

REV

MATERIAL: NORYL

TWO PLACE DECIMAL ± \*\*\*  
THREE PLACE DECIMAL ± \*\*\*

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1201E-RP](#)