

1. SPECIFICATION

AZ-1340E-P21


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	1~ 25	
03	Rated Current	mA(Max)	5	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	75	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4000± 300	Rated Voltage
06	Capacitance	pF	12000±30%	At 120Hz

REV NO.




REVISION NOTE

APPROVAL

DATE

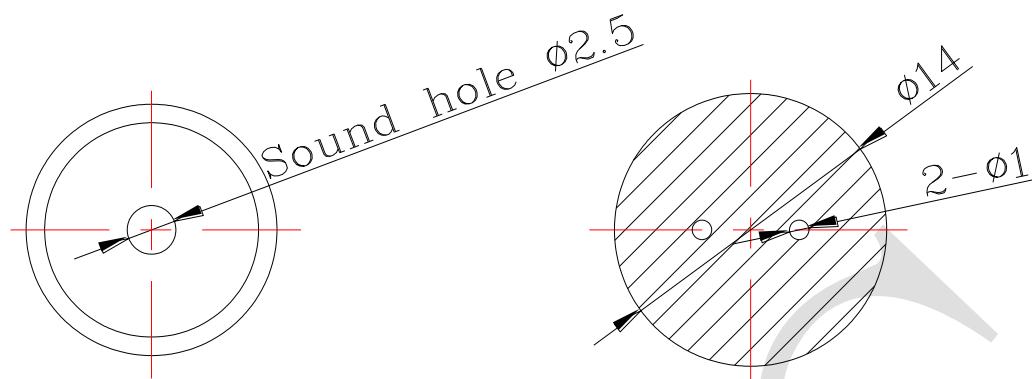

RECOMMEND PCB LAYOUT

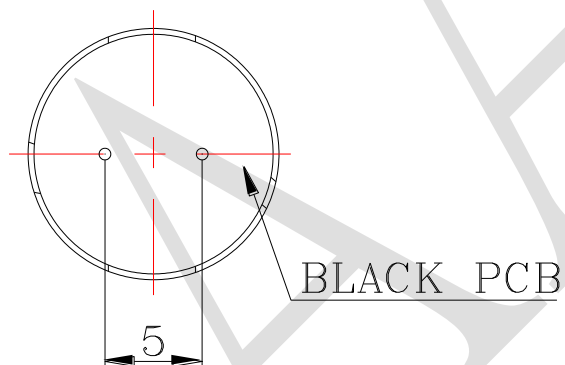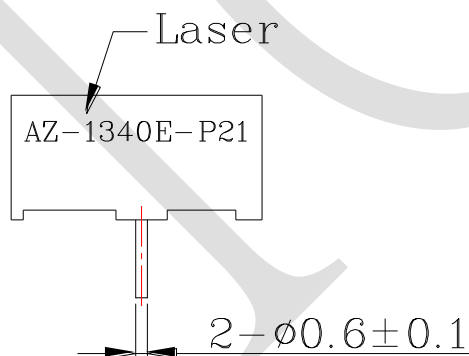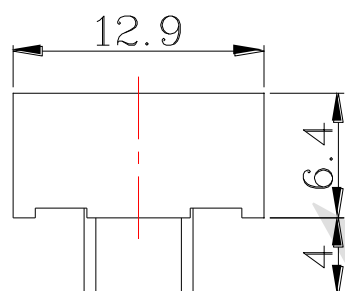

RoHS

TITLE: PIEZO BUZZER

DRAWN: Zack

2017/10/27

SCALE: 2:1

SHEET: 1:1

PART NO. AZ-1340E-P21

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. BP1360-40B(011-136022-02)

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

MATERIAL: PPO



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1340E-P21](#)