

1. SPECIFICATION

AZ-3034E-W4


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	3~ 28	
03	Rated Current	mA(Max)	5	Rated Voltage
04	Sound pressure level (Distance at 30cm)	dBA(Min)	85	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	3400± 500	Rated Voltage
06	Capacitance	pF	20000±30%	At 120Hz

REV NO.

REVISION NOTE

APPROVAL

DATE

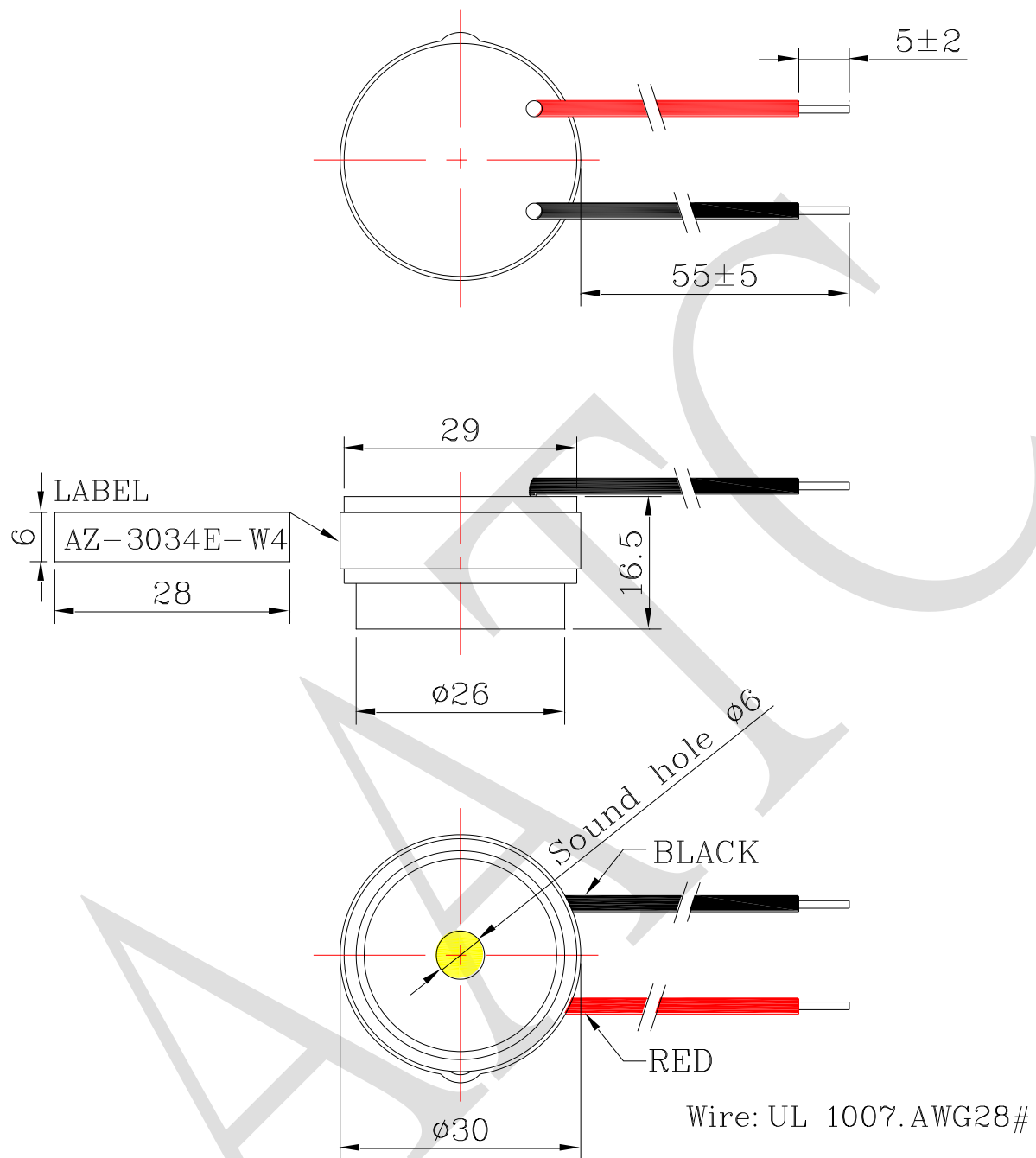

RoHS

TITLE: PIEZO BUZZER

DRAWN: Jerry 2013/08/13

SCALE: 2:1 SHEET: 1:1

PART NO. AZ-3034E-W4

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. TYE3034CSL60

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: ABS

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-3034E-W4](#)