


1. SPECIFICATION

APD-1305-PA (RoHS)

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	Vp-p (Square Wave)
02	Operating Voltage	V	3~ 25	
03	Rated Current	mA(Max)	8	Rated Voltage
04	Sound Output (Distance at 10cm)	dBA(Min)	70	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4100± 500	Rated Voltage
06	Capacitance	pF	16000±30%	At 100Hz

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

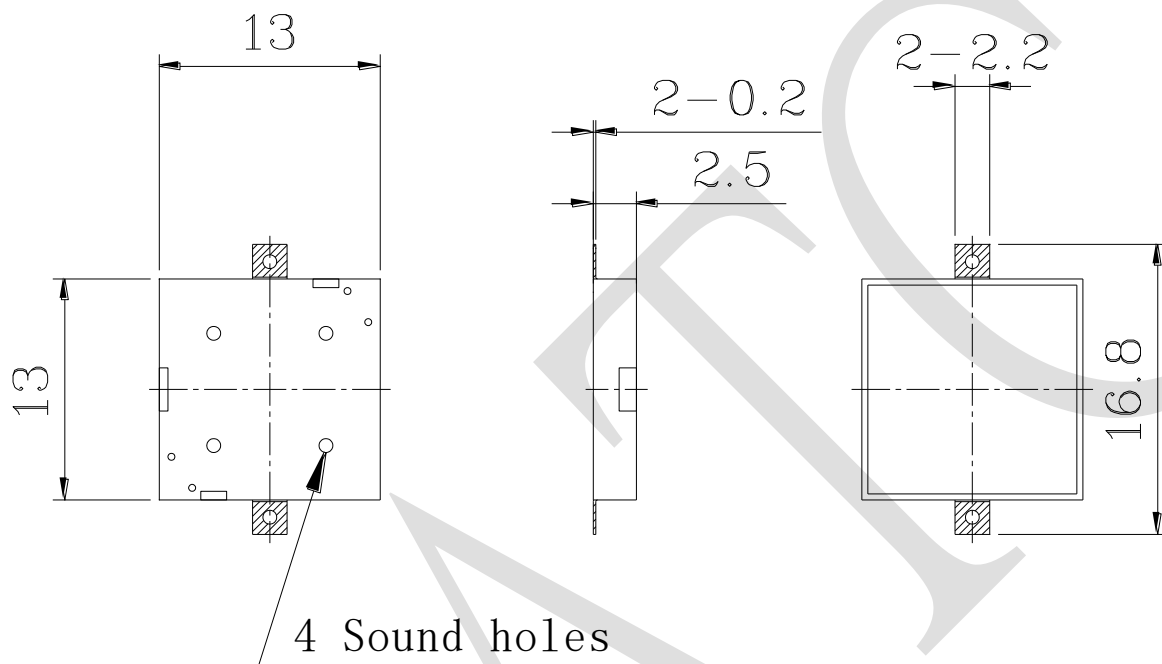

PCB LAYOUT

RoHS

TITLE: SMD PIEZO BUZZER		DRAWN: Zack	2014/03/25	SCALE: 2:1	SHEET: 1 of 1
PART NO. APD-1305-PA	2	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. FD-110413		CHECKED:		TOLERANCE ± 0.3	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: LCP		ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[APD-1305-PA](#)