
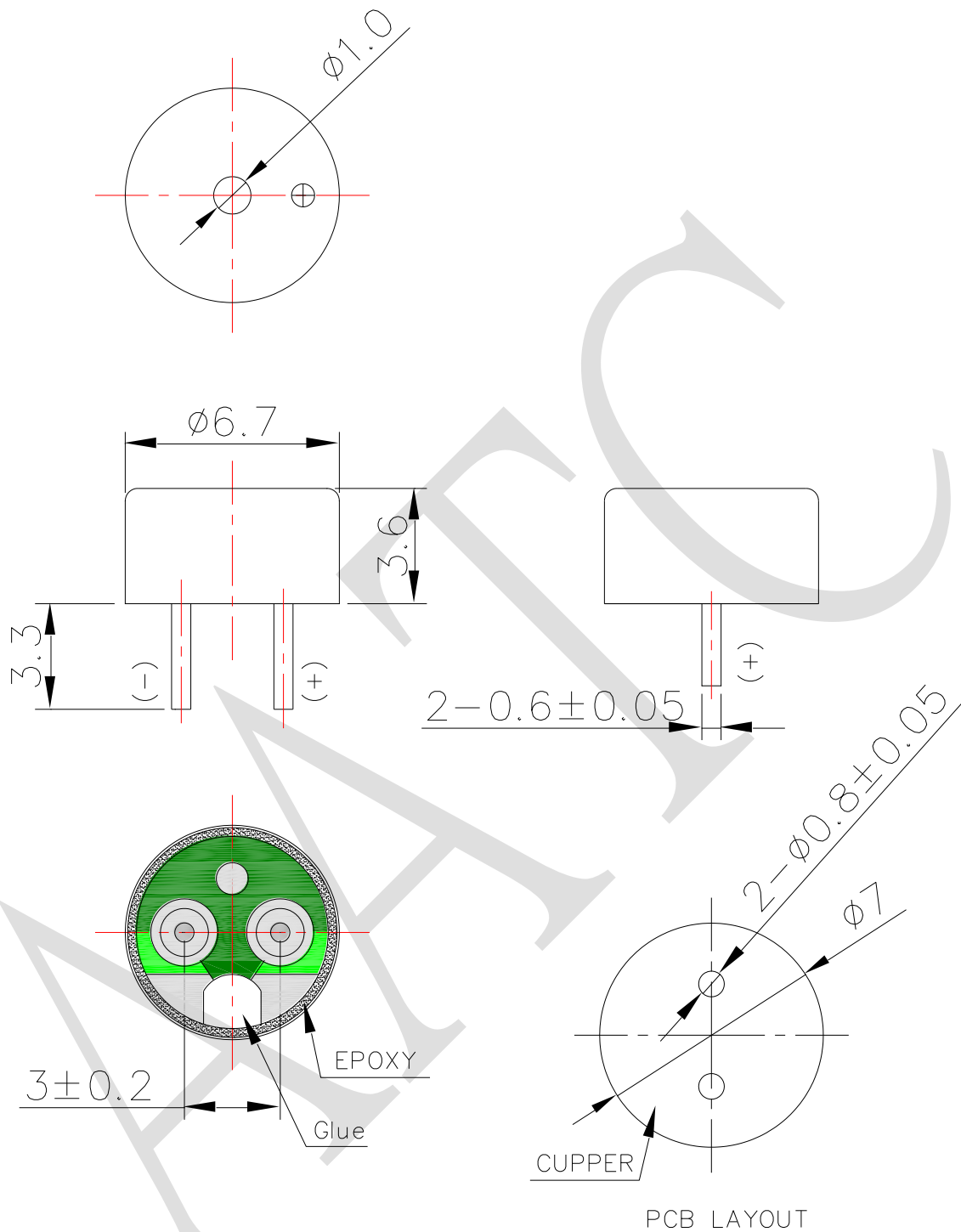


1. SPECIFICATION

AC-701X-P

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.0	
02	Operating Voltage	V	1 ~ 3	
03	Consumption Current	mA (Max)	Mean : 30	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 90	
04	Direct Current Resistance	Ω	25 \pm 3	
05	Sound pressure level (Distance at 10cm)	dBA (Min)	63	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2730	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Jerry	2013/01/03	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-701X-P		2	DESIGNED: R&D OF AAT	UNITS: mm	
DWG NO.UGCM0601AP3.3D-R25			CHECKED:	TOLERANCE ± 0.5	
			APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
REV			MATERIAL: NORYL	ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)
[AC-701X-P](#)