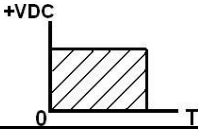
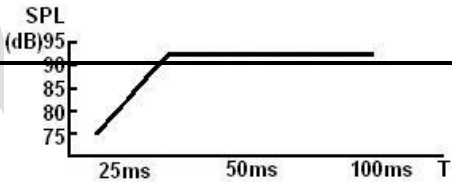


1. SPECIFICATION

AX-903-P




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	
02	Operating Voltage	V	2 ~ 5	
03	Consumption Current	mA (Max)	Mean : 30	Rated Voltage
			Peak : 90	
04	Sound pressure level	dB(A) (Min)	80	Distance at 10cm
05	Resonant Frequency	Hz	3000 ±300	

REV NO.

REVISION NOTE

APPROVAL

DATE

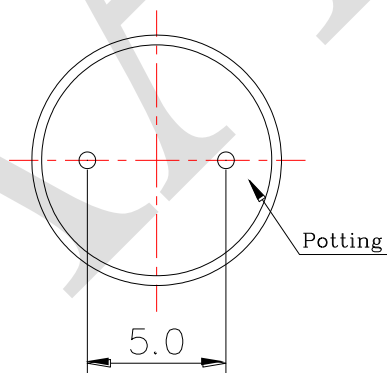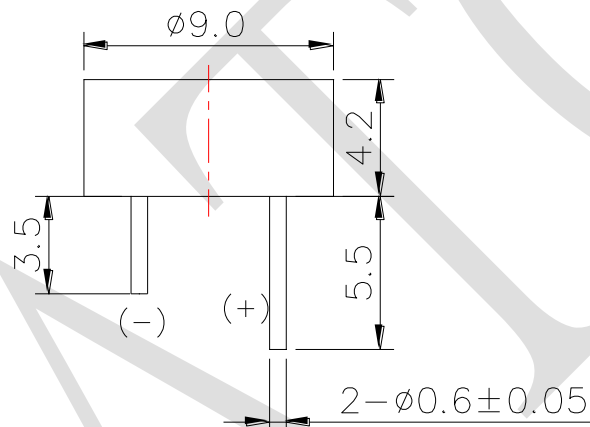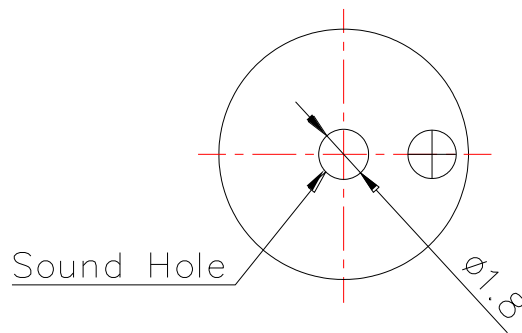

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Zack

2013/06/06

SCALE: 4:1

SHEET: 1 of 1

PART NO. AX-903-P

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: PPO

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

DWG NO. FDM-2656 FDB-090042F-03030

2
REV

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)
[AX-903-P](#)