 


1. SPECIFICATION

AC-1205G-N1LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	<div><p>Standard state, standard drive circuit. Square wave 1/2 duty.</p></div>
02	Operating Voltage	V	3 ~ 8	
03	Consumption Current	mA Max.	40	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	85	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	40±6	
06	Rated Frequency	Hz	2400	

REV NO.

REVISION NOTE

APPROVAL

DATE

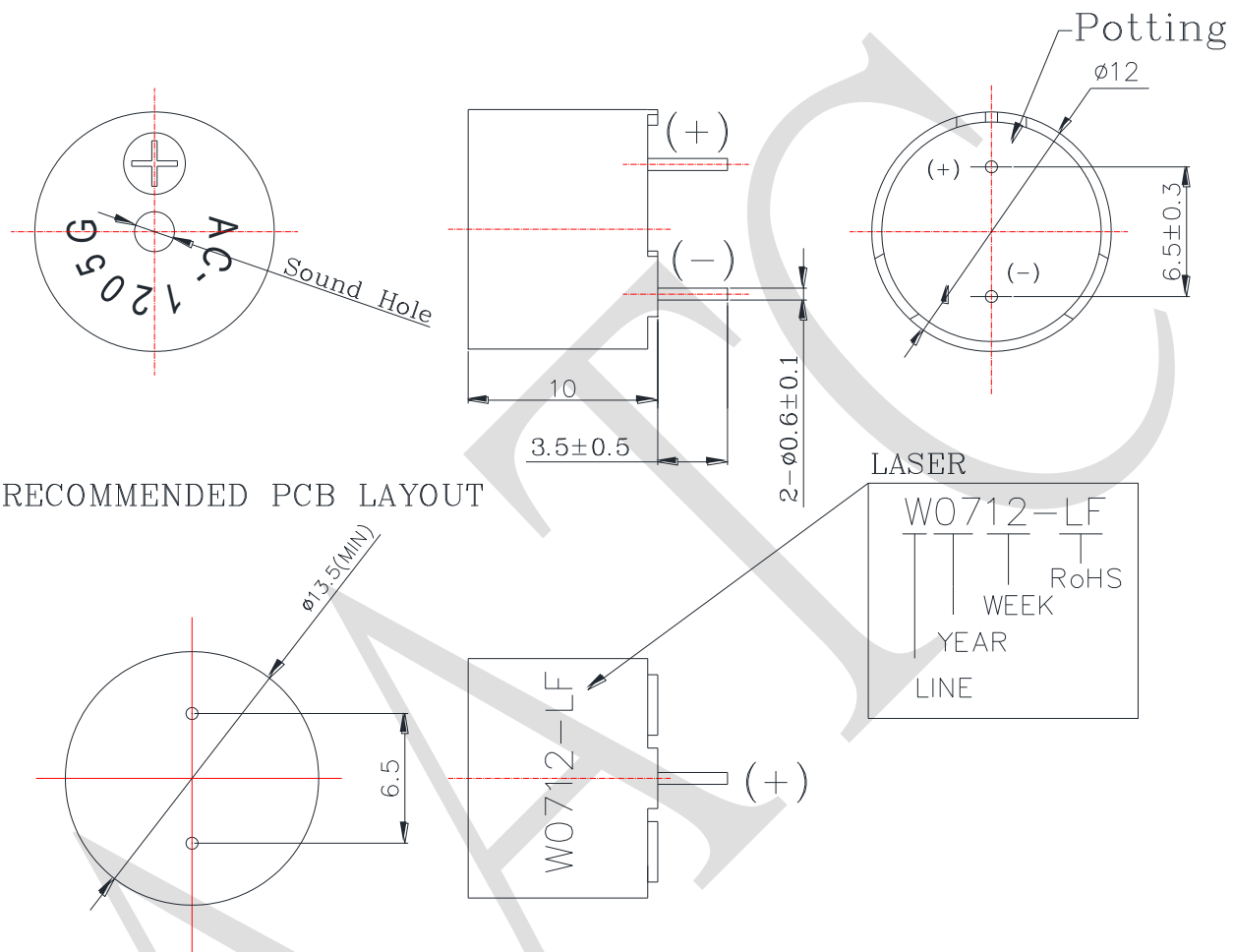

RECOMMENDED PCB LAYOUT

RoHS

TITLE: MAGNETIC BUZZER		DRAWN: Handk	2020/02/19	SCALE: 3:1	SHEET: 1 OF 1
PART NO. AC-1205G-N1LF	6	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. UGCM1205AP3.5BH10-R40		CHECKED:	TOLERANCE ± 0.5		
REV		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
		MATERIAL: PBT	ONE PLACE DECIMAL \pm ***		
			TWO PLACE DECIMAL \pm ***		
			THREE PLACE DECIMAL \pm ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AC-1205G-N1LF