


1. SPECIFICATIONS

AMF-O97A36-NB1

01	Electret's Type	Foil type
02	Sensitivity	-36±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	4.5 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	100 - 20K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=4.5 to 4.0V
10	S/N Ratio	≥58dB
11	Sound Pressure Level	110 dB

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

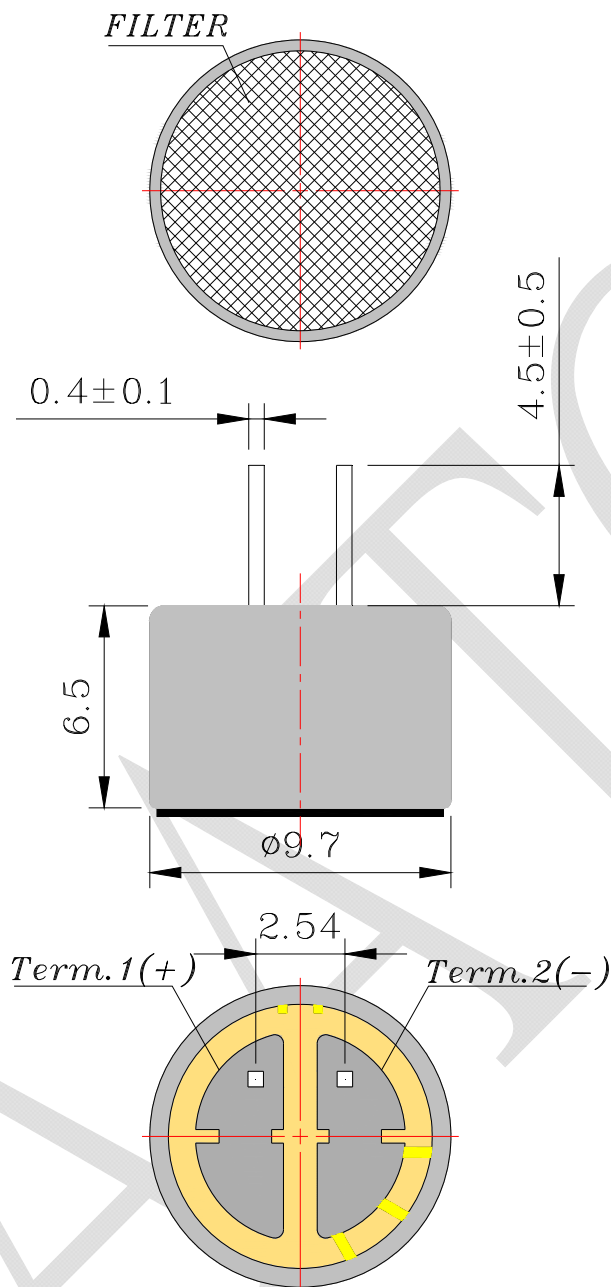

RoHS

TITLE: MICROPHONE		DRAWN: Zack	2015/01/23	SCALE: 5:1	SHEET: 1 of 1
PART NO. AMF-097A36-NB1	1	DESIGNED: R & D OF AAT		UNITS: mm	
		CHECKED:		TOLERANCE ± 0.3	
DWG NO. F9765AP(P=4.5) 6995	REV	APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: *****		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AMF-O97A36-NB1](#)