 
 



1. SPECIFICATION

AZ-1440S-P13

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	3 ~ 7	
03	Consumption Current	mA (Max)	10	Rated Voltage
04	Resonant Frequency	Hz	4000 ± 500	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	80	Distance at 10cm Rated Voltage / Resonant Frequency

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

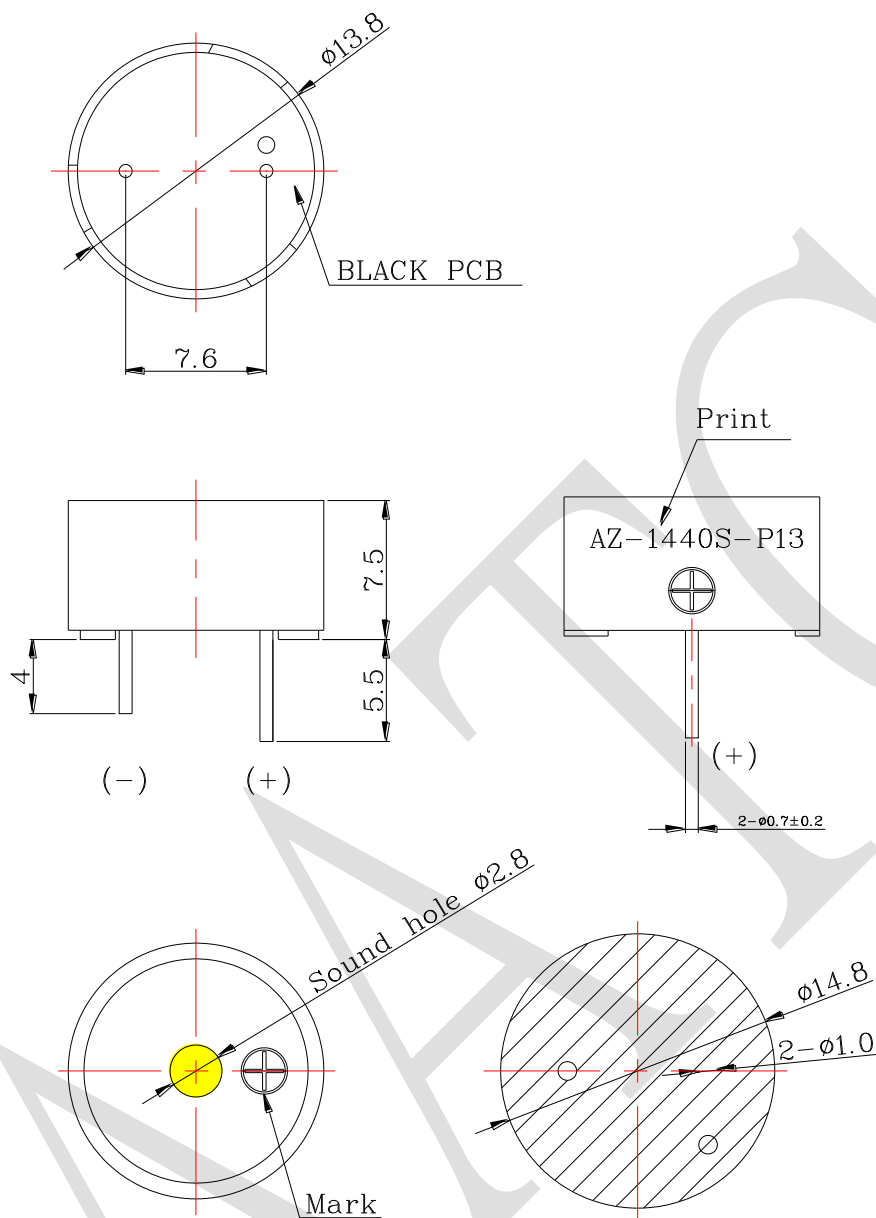

RECOMMENDED PCB LAYOUT

RoHS

TITLE:	PIEZO BUZZER	DRAWN:	Zack	2019/08/08	SCALE:	2:1	SHEET:	1 of 1
PART NO.	AZ-1440S-P13	DESIGNED:	R & D OF AAT		UNITS:	mm		
		CHECKED:			TOLERANCE	± 0.5		
		APPROVAL:			UNLESS OTHERWISE SPECIFIED:			
DWG NO.	BPC1475-0540(021-147536-00)	MATERIAL:	PBT		ONE PLACE DECIMAL	± ***		
					TWO PLACE DECIMAL	± ***		
					THREE PLACE DECIMAL	± ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1440S-P13](#)