

1. SPECIFICATION

AZ-4228S-C9-LF


| ITEM |                                              | UNITS    | SPECIFICATIONS | CONDITIONS                       |
|------|----------------------------------------------|----------|----------------|----------------------------------|
| 01   | Rated Voltage                                | V        | 12             | VDC                              |
| 02   | Operating Voltage                            | V        | 3~ 28          |                                  |
| 03   | Rated Current                                | mA(Max)  | 9              | Rated Voltage                    |
| 04   | Sound pressure level<br>(Distance at 100cm ) | dBA(Min) | 85             | Rated Voltage<br>Rated Frequency |
| 05   | Rated Frequency                              | Hz       | 2800           | Rated Voltage                    |
| 06   | Resonant Frequency                           | Hz       | 2800 ± 500     |                                  |

REV NO.

REVISION NOTE

APPROVAL

DATE

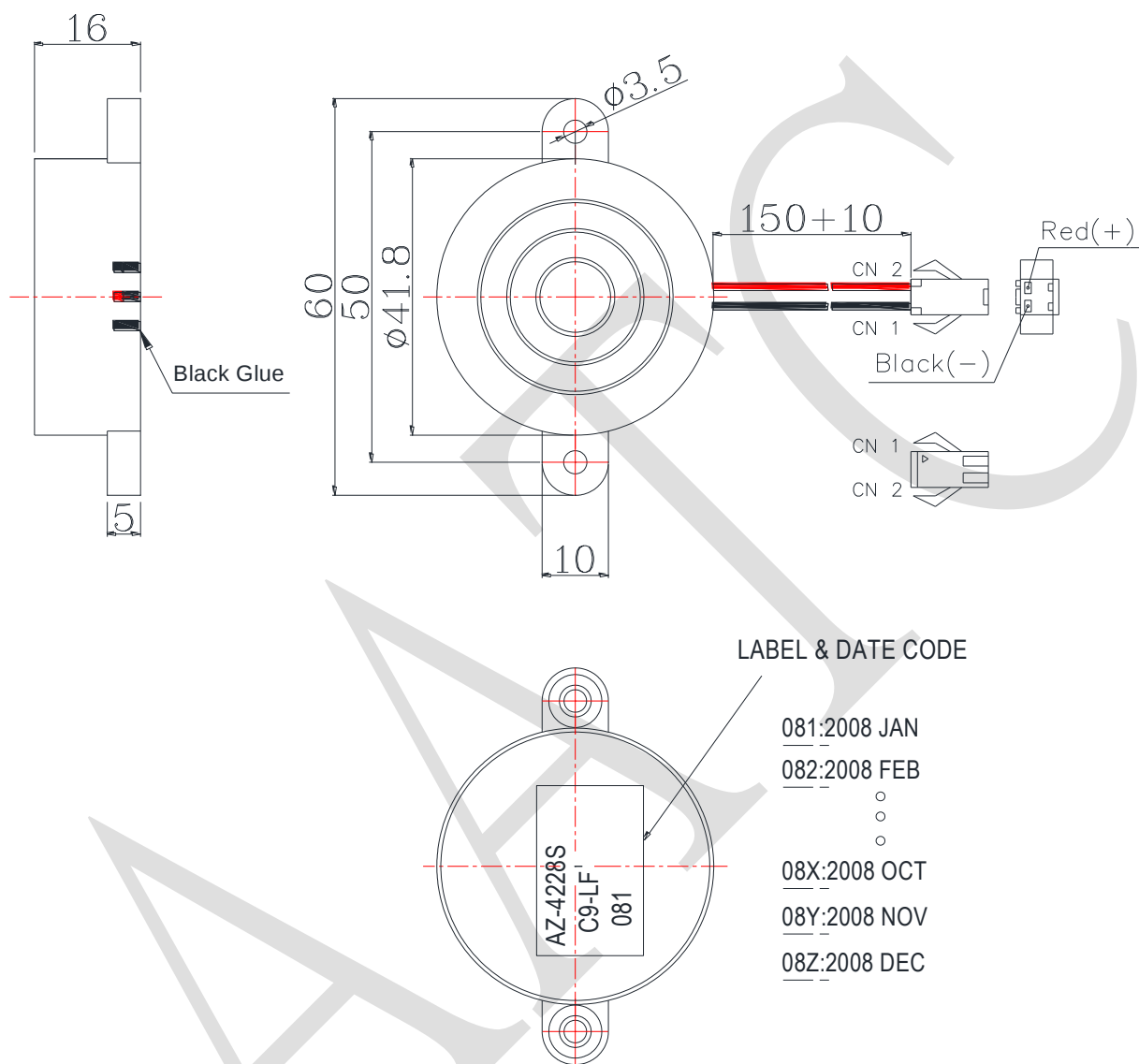

WIRE : UL 1007 , 24 AWG ..

CONNECTOR : Equivalent to JST SMP-02V-NC (White)

RoHS

|                                |                                  |          |                                   |                                                                                                                            |               |  |
|--------------------------------|----------------------------------|----------|-----------------------------------|----------------------------------------------------------------------------------------------------------------------------|---------------|--|
| TITLE: <i>PIEZO BUZZER</i>     |                                  | 3<br>REV | DRAWN: <b>Hank</b> 2020/02/18     | SCALE: 2:1                                                                                                                 | SHEET: 1 of 1 |  |
| PART NO. <i>AZ-4228S-C9-LF</i> | DWG NO. <i>UGPA42CX2812WC150</i> |          | DESIGNED: <i>R &amp; D OF AAT</i> | UNITS: <i>mm</i>                                                                                                           |               |  |
|                                |                                  |          | CHECKED:                          | TOLERANCE $\pm 0.5$                                                                                                        |               |  |
|                                |                                  |          | APPROVAL:                         | UNLESS OTHERWISE SPECIFIED:<br>ONE PLACE DECIMAL $\pm$ ***<br>TWO PLACE DECIMAL $\pm$ ***<br>THREE PLACE DECIMAL $\pm$ *** |               |  |
|                                |                                  |          | MATERIAL: <i>ABS</i>              |                                                                                                                            |               |  |



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-4228S-C9-LF