

1. SPECIFICATIONS

AMB-O40J42-7CWH3


01	Sensitivity	-42±3dB (0dB=1V/Pa,1KHz)
02	Standard Operation Voltage	2.0 V
03	Output Impedance	2.2 KΩ
04	Directivity	Omni directional
05	Frequency Range	100 - 10K Hz
06	Max. Operation Voltage	10V
07	Current Consumption	Max.0.5mA
08	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
09	S/N Ratio	≥58dB
10	Sound Pressure Level	110 dB
11	Operating Temperature	-20~+60℃
12	Storage Temperature	-25~+70℃

REV NO.

REVISION NOTE

APPROVAL

DATE

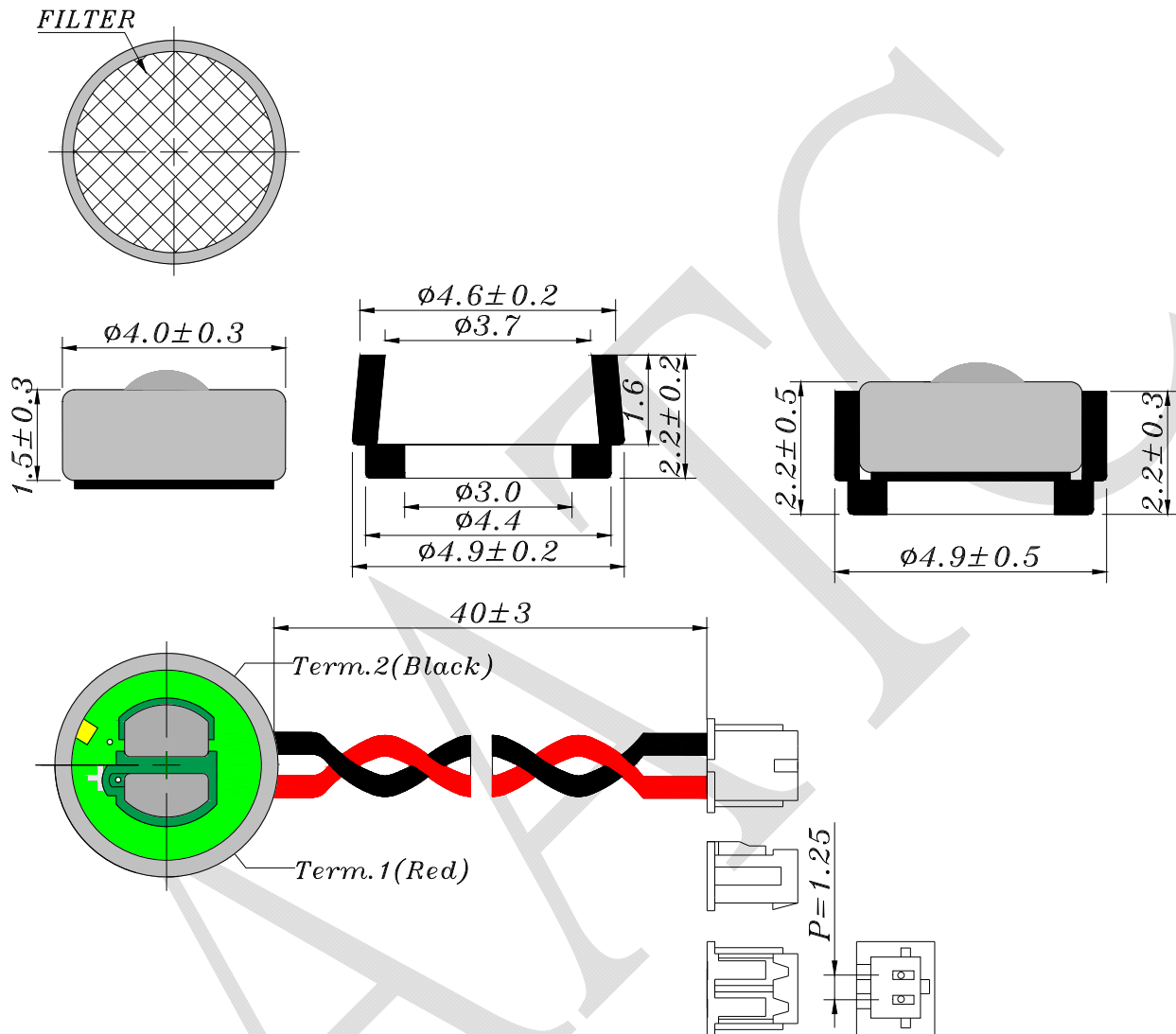

WIRE: UL1571,AWG30#
 CONNECTOR:Molex 51021-0200
 Holder: DD-EQ-JTA49-07

RoHS

TITLE: MICROPHONE		DRAWN: Jack	2018/11/20	SCALE: 5:1	SHEET: 1 of 1
PART NO. AMB-040J42-7CWH3		DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. T4015AL-SMN-D42-M		CHECKED:		TOLERANCE ± 0.3	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: AL		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AMB-O40J42-7CWH3](#)