
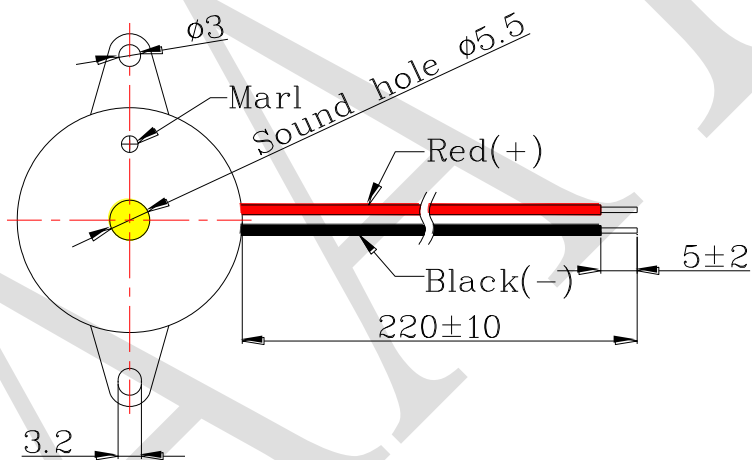
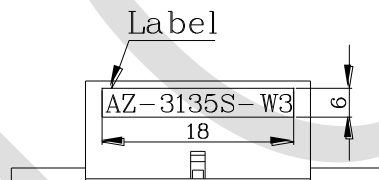
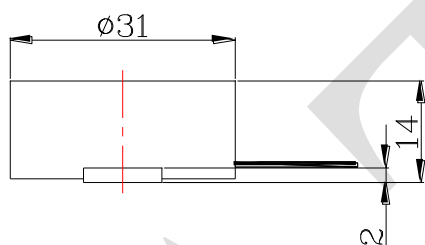


1. SPECIFICATION

AZ-3135S-W3

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	VDC
02	Operating Voltage	V	3~ 20	
03	Rated Current	mA(Max)	9	Rated Voltage
04	Sound pressure level (Distance at 30cm)	dBA(Min)	95	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	3500	Rated Voltage
06	Resonant Frequency	Hz	3500± 500	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

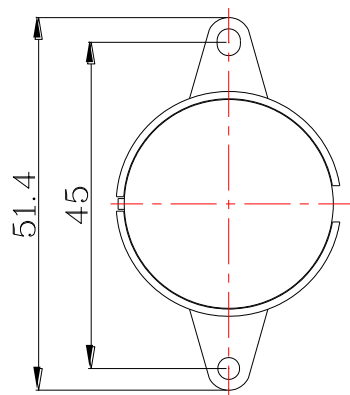

Wire: UL 1095 AWG28#

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Zack	2015/01/21	SCALE: 2:1	SHEET: 1 of 1
PART NO. <i>AZ-3135S-W3</i>	1	DESIGNED: <i>R & D OF AAT</i>		UNITS: <i>mm</i>	
		CHECKED:		TOLERANCE ± 0.5	
DWG NO. <i>UGPA31AX3509W220</i>		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: <i>ABS</i>		ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-3135S-W3](#)