

1. SPECIFICATION

AZ-2434S-PH-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	3 ~ 20	
03	Rated Current	mA(Max)	9	Rated Voltage
04	Sound pressure level (Distance at 30cm)	dBA(Min)	90	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	3400	Rated Voltage
06	Resonant Frequency	Hz	3400 ± 500	

REV NO.

REVISION NOTE

APPROVAL

DATE

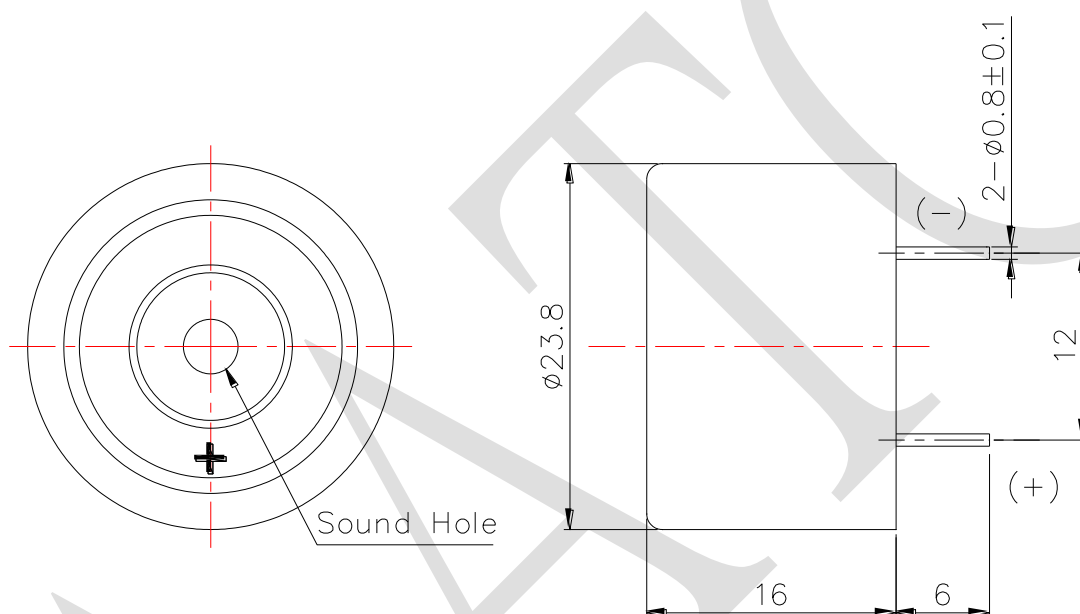

RoHS

TITLE: *PIEZO BUZZER*DRAWN: **Zack** 2014/05/28

SCALE: 2:1 SHEET: 1 of 1

PART NO. *AZ-2434S-PH-LF*DESIGNED: *R & D OF AAT*UNITS: *mm*DWG NO. *UGPM24DX3412P-P12*

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

REV

MATERIAL: *NORYL*ONE PLACE DECIMAL \pm ***
TWO PLACE DECIMAL \pm ***
THREE PLACE DECIMAL \pm ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-2434S-PH-LF