


1. SPECIFICATION

AK-150810-PM-3C2

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 15 mm	
03	Rated Input Power	1.0 W	
04	Max. Input Power	1.5 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$ at 2KHz 1V	
06	Resonance Frequency (Fo)	1200Hz $\pm 20\%$ at Fo, 1V	
07	Sound pressure level	86 dB(0.1W/0.1M) ± 3 dB	at AVE 1.0, 1.5, 2.0, 2.5 KHz.
		95 dB(1.0W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 20 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.0W(2.83v rms).	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

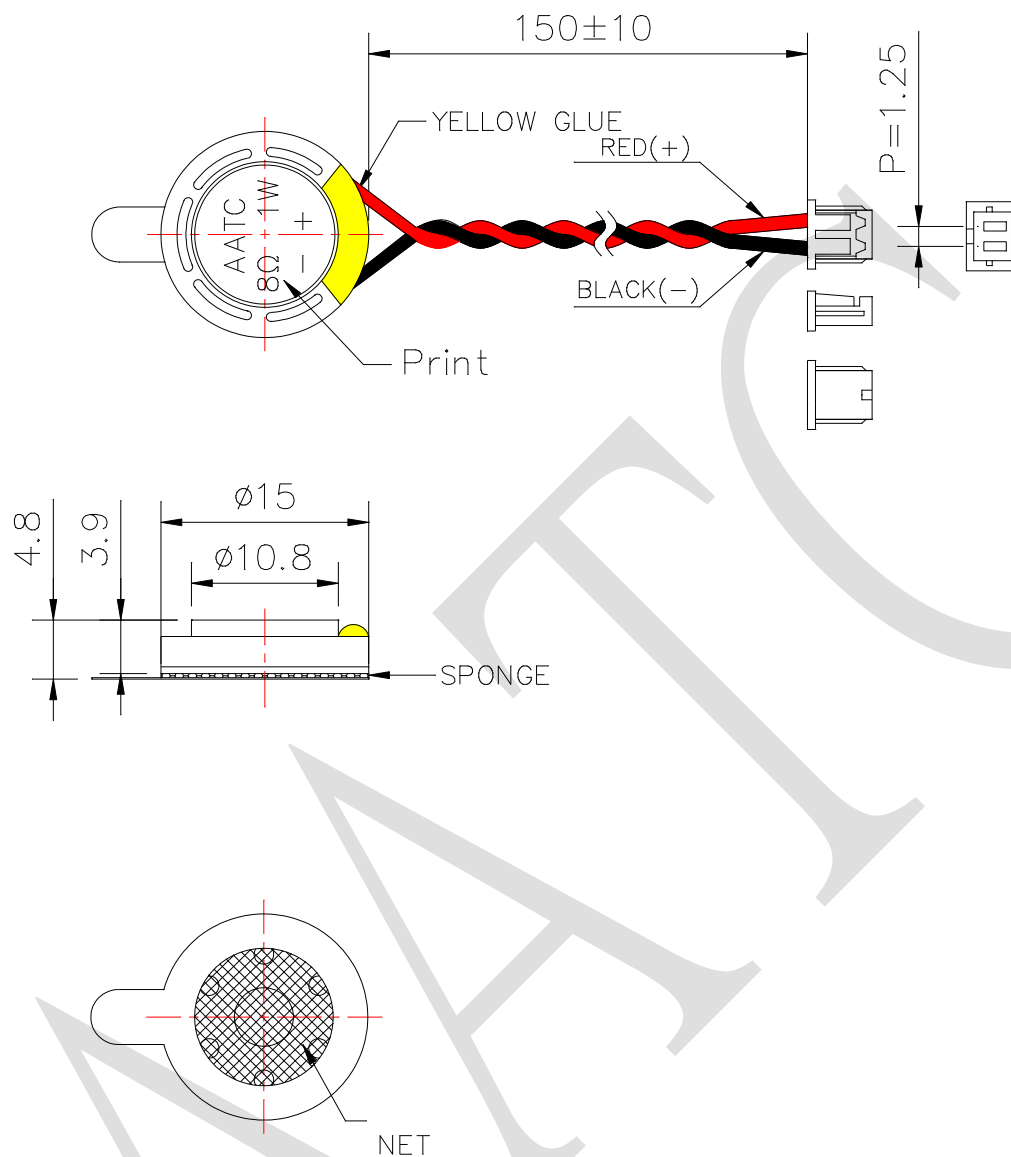

WIRE: UL1571,AWG30#
CONNECTOR:Equivalent to MOLEX 51021-0200

TITLE:	DYNAMIC SPEAKER	DRAWN:	Sunny	2016-11-24	SCALE: 2:1	SHEET: 1 of 1
PART NO.	AK-150810-PM-3C2	DESIGNED:	R&D OF AAT		UNITS:	mm
DWG NO.	CA-K16112401	CHECKED:			TOLERANCE	± 0.5
		APPROVAL:			UNLESS OTHERWISE SPECIFIED:	ONE PLACE DECIMAL ± ***
		MATERIAL:	PBT			TWO PLACE DECIMAL ± ***
						THREE PLACE DECIMAL ± ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-150810-PM-3C2](#)