


1. SPECIFICATION



AR-20150AA-2W (RoHS)

ITEM		SPECIFICATIONS
01	Type	Dynamic 20mm receiver unit
02	SENSITIVITY (S.P.L)	92 dB \pm 3 dB at 1KHz 100mV with IEC318 coupler.
03	Impedance	150 Ω \pm 15% at 1.0 KHz
04	Frequency Range	100 – 10K Hz
05	Rated Input Power	30 m W
06	Max. Input Power	50 m W
07	Total Harmonics Distortion	Max 5% at 1 KHz, 100 mV.

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

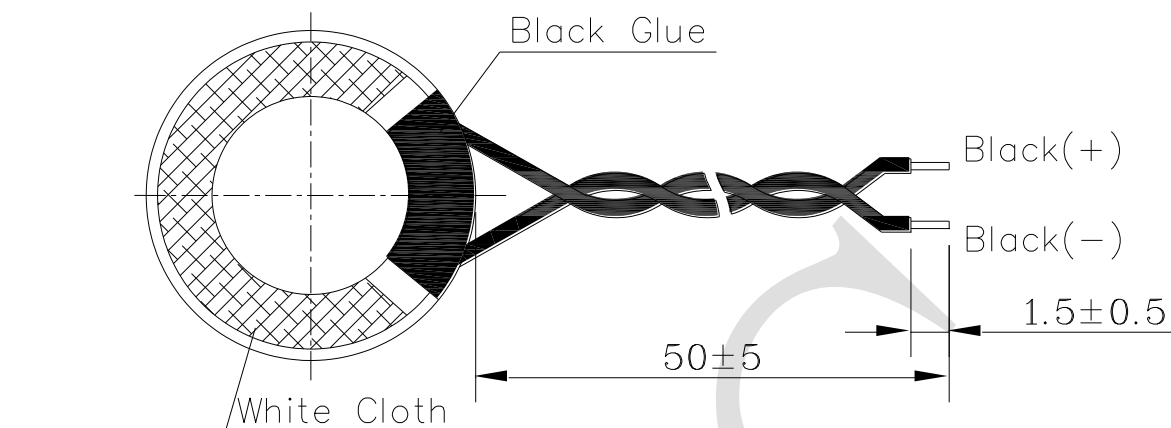

Wire: UL1571, 30AWG

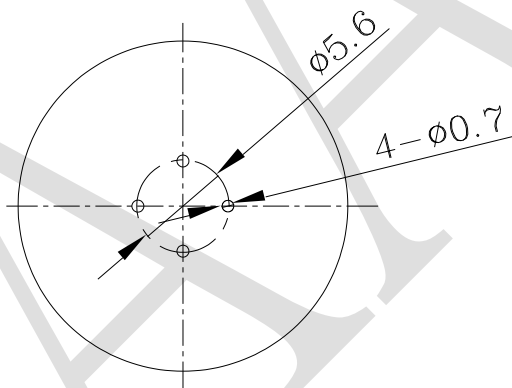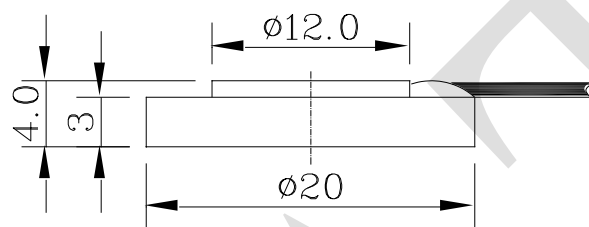

RoHS

TITLE: DYNAMIC RECEIVER		DRAWN: Jason	2011/08/23	SCALE: 3:1	SHEET: 1 of 1
PART NO. AR-20150AA-2W	2	DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. HS-110823		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: ABS		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



苙翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AR-20150AA-2W