


1. SPECIFICATION

AKB-282808E-1W1

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 28X28 mm	
03	Rated Input Power	3.0 W	
04	Max. Input Power	4.0 W for 1 minute	
05	Impedance	8Ω ± 15% at 1.0KHz 1V	
06	Resonance Frequency (Fo)	800 Hz ± 20% at Fo, 1V	
07	Sound pressure level	88 dB(0.1W/0.1M) ± 3 dB	at AVE 0.8K 1.0K 1.2K 1.5KHz.
		99 dB (3.0W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 6 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 4.89V.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

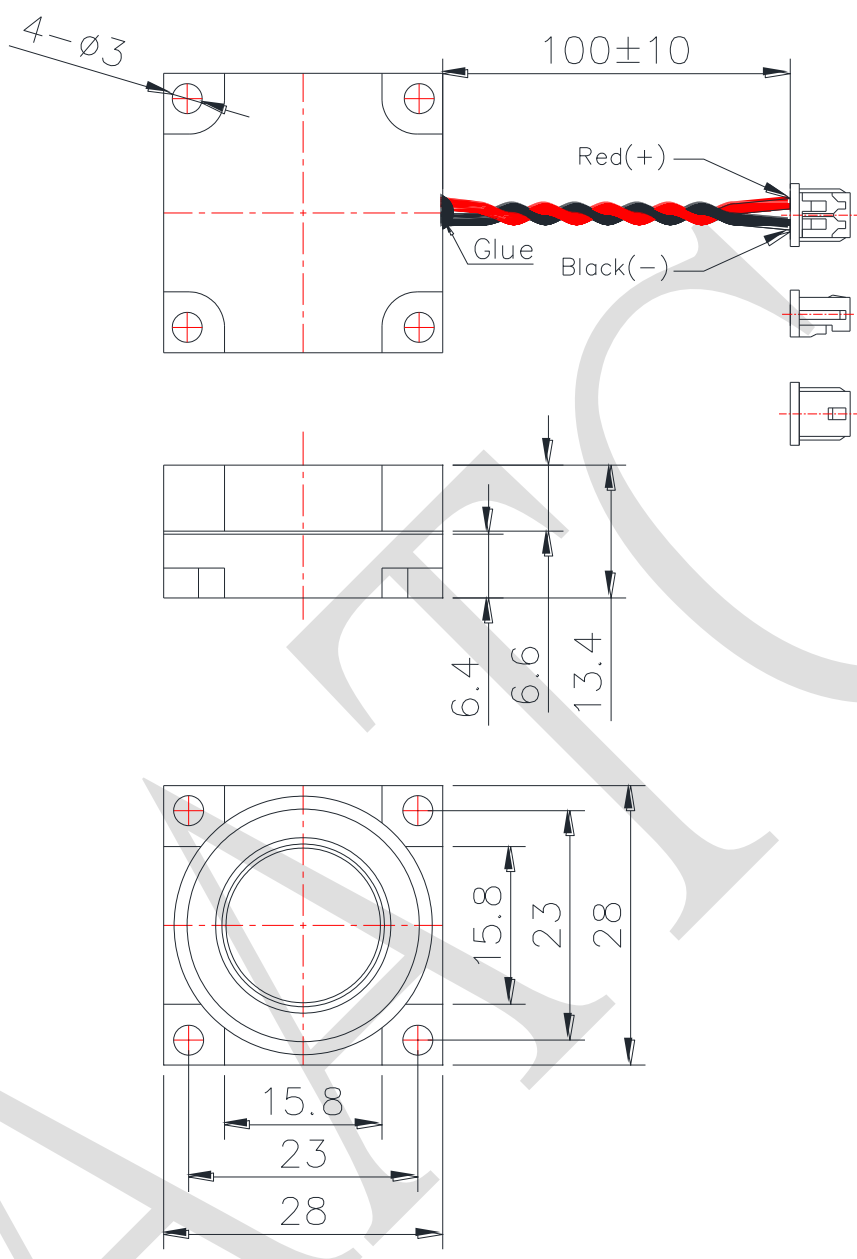

Wire: UL 1571,AWG30#
CONNECTOR: Molex 51021-0200

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2015/04/15	SCALE: 2:1	SHEET: 1:1
PART NO. AKB-282808B-1W1	1	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. CXS2828134LP100-R08W3.0-A		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL ± *** TWO PLACE DECIMAL ± *** THREE PLACE DECIMAL ± ***	
	REV	MATERIAL: ABS			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKB-282808B-1W1](#)