


1. SPECIFICATION

AKR-28280420-MMPU-1

ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Rated Input Power	2.0 W	
03	Max. Input Power	3.0W for 1 minute	
04	Impedance	$4\Omega \pm 15\%$ at 1KHz 1V	
05	Resonance Frequency (Fo)	400Hz $\pm$ 20% at Fo, 1V	
06	Sound pressure level	94dB(2.0W/0.1M) $\pm$ 3 dB	at AVE0.8, 1.0, 1.2, 1.5 KHz.
07	Frequency Range	Fo –20K Hz	
08	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.0W.	
09	Voice Coil	Diameter15mm	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

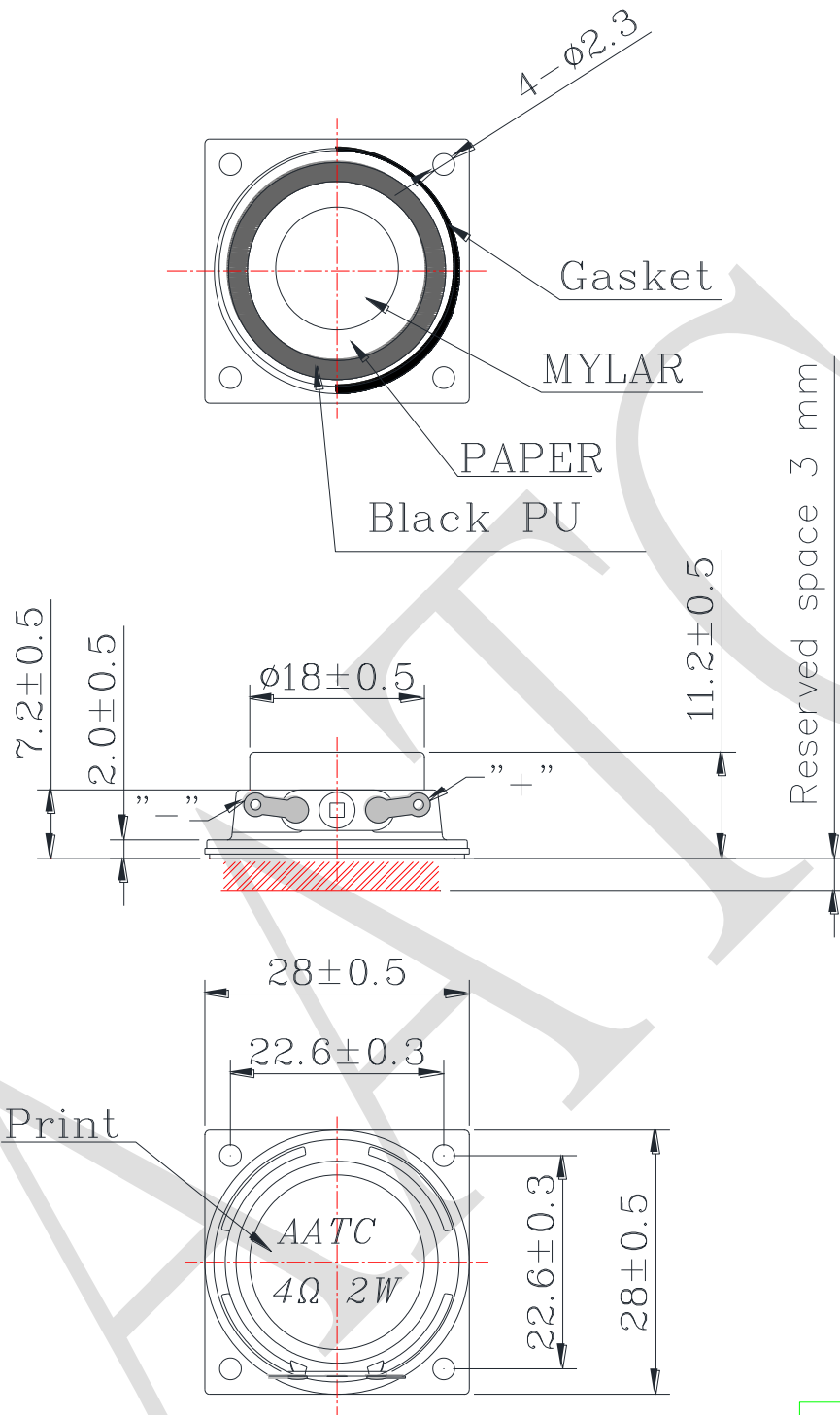

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Moose	2015/12/01	SCALE: 2:1	SHEET: 1:1
PART NO.	1	DESIGNED: R&D OF AAT	UNITS: mm		
AKR-28280420-MMPU-1		CHECKED:	TOLERANCE ± 0.3		
DWG NO.		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
CXS2828112-R04W2.0-B		REV	MATERIAL: SPCC	ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKR-28280420-MMPU-1](#)