

1. SPECIFICATION

AK-180805-PM-2C


ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 18 mm	
03	Rated Input Power	0.5 W	
04	Max. Input Power	1.0 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$ at 1KHz 1V	
06	Resonance Frequency (Fo)	950 Hz $\pm$ 20% at Fo, 1V	
07	Sound pressure level	92 dB(0.5W/0.1M) $\pm$ 3 dB	at AVE 1.0K,1.2K,1.5,1.8KHz.
08	Frequency Range	Fo -20 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.1W	

REV NO.

REVISION NOTE

APPROVAL

DATE

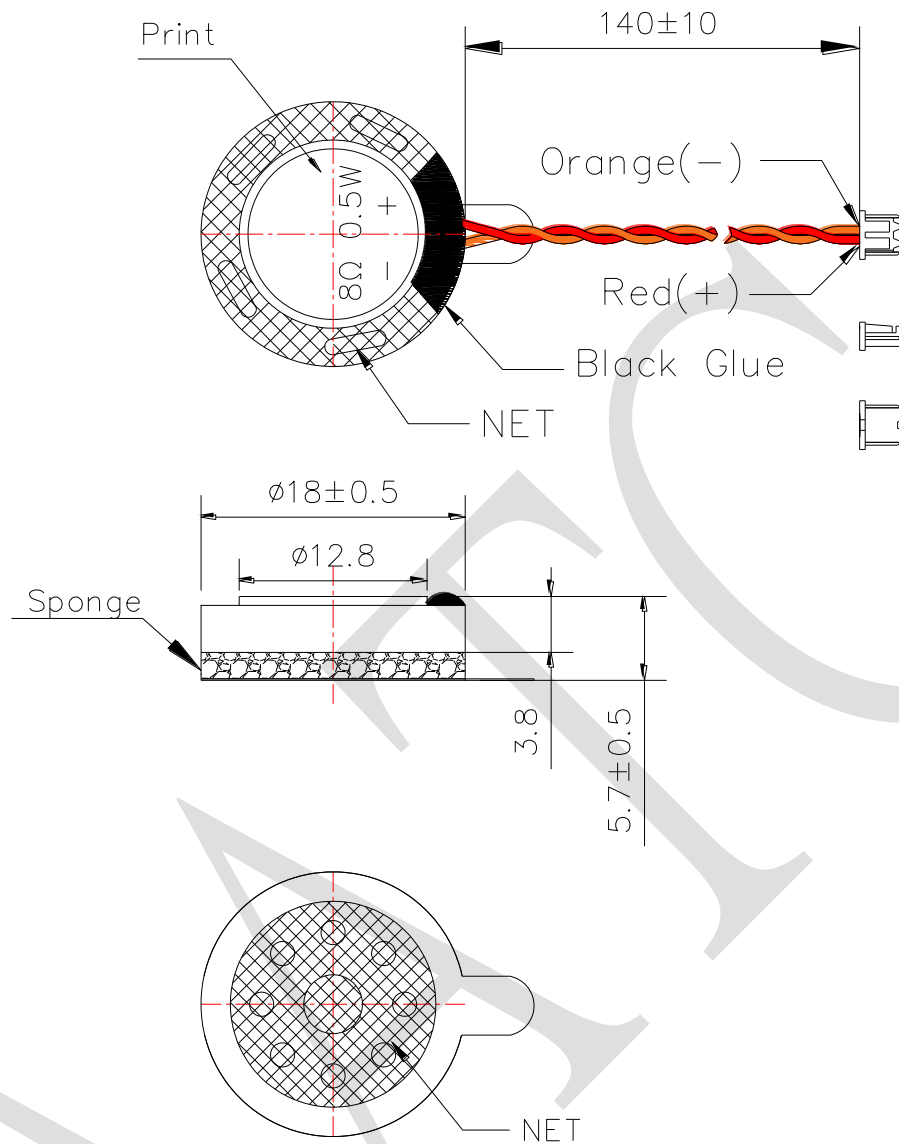

Wire: UL 1571, AWG28#

Connector: Equivalent to Molex 51021-0200

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Zack 2017/03/07

SCALE: 2:1 SHEET: 1:1

PART NO. AK-180805-PM-2C

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. CXS18057LP140-R08W0.5-F

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: PBT

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AK-180805-PM-2C](#)