


1. SPECIFICATION

AR-1032RA-6 (RoHS)

ITEM		SPECIFICATIONS
01	Type	Dynamic 10mm receiver unit
02	SENSITIVITY (S.P.L)	110 dB ±3 dB at 1KHz 180mV with IEC318 coupler.
03	Impedance	32 Ω ± 15% at 1.0 KHz
04	Frequency Range	100 – 10K Hz
05	Rated Input Power	10 m W
06	Max. Input Power	20 m W
07	Total Harmonics Distortion	Max 10 % at 1 KHz, 180 mV.

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

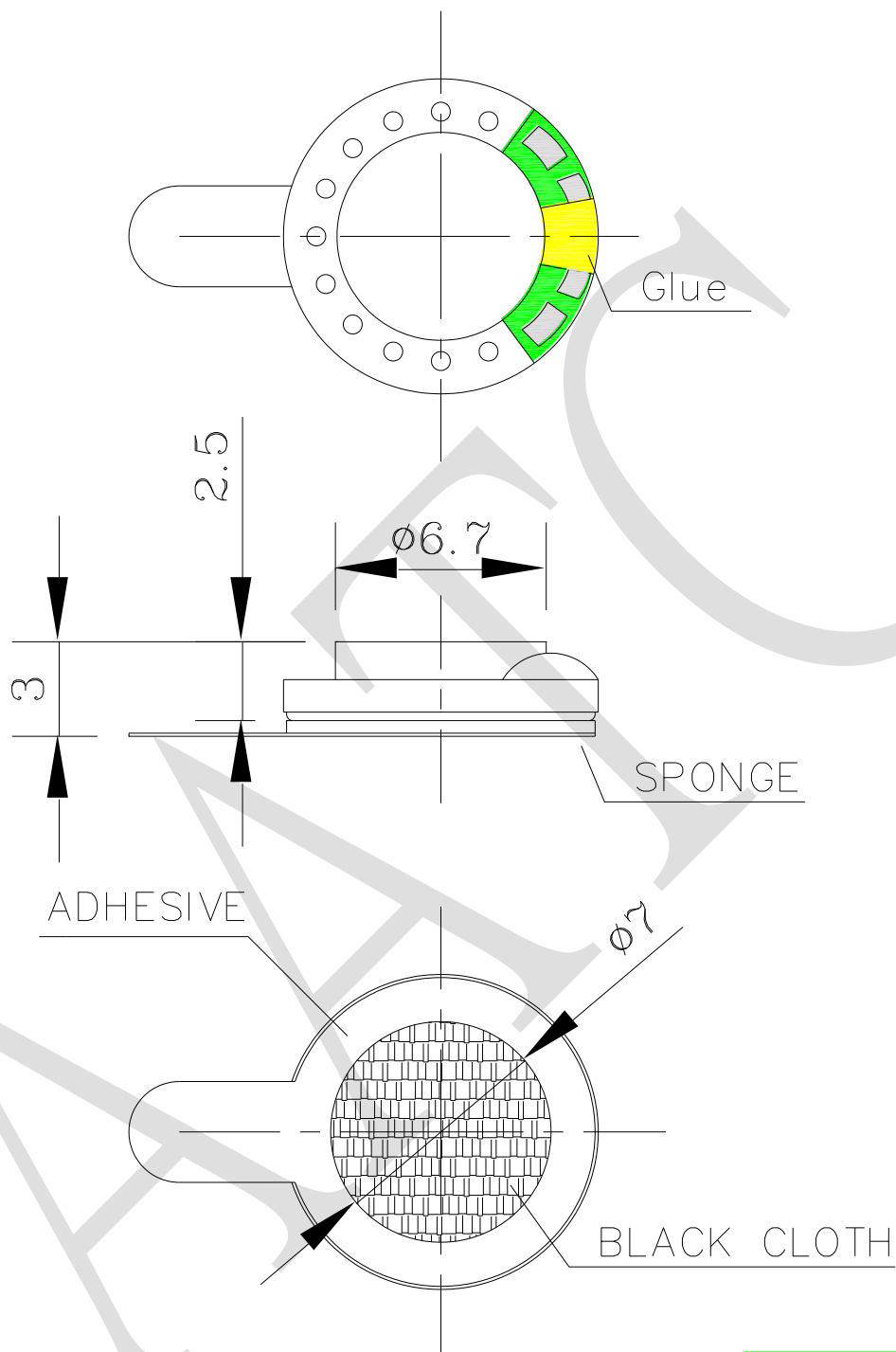

RoHS

TITLE: DYNAMIC RECEIVER		DRAWN: JOHN	2010/10/11	SCALE: 3:1	SHEET: 1 of 1
PART NO. AR-1032RA-6	1	DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. HS-101011		CHECKED:		TOLERANCE ± 0.3	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: *****		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



苙翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AR-1032RA-6](#)