


1. SPECIFICATION

AKV-22090810-PM-1W

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter22 x 09mm	
03	Rated Input Power	1.0 W	
04	Max. Input Power	1.2 W for 1 minute	
05	Impedance	8Ω± 15% at 1KHz 1V	
06	Resonance Frequency (Fo)	1350 Hz ± 20% at Fo, 1V	
07	Sound pressure level	80 dB(0.1W/0.1M) ± 3 dB	at AVE 1.0K, 1.2K, 1.5K, 2.0 KHz.
		90 dB(1.0W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 20 K Hz	
09	Total Harmonics Distortion	Max 10 % at 2 KHz, 1.0W.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

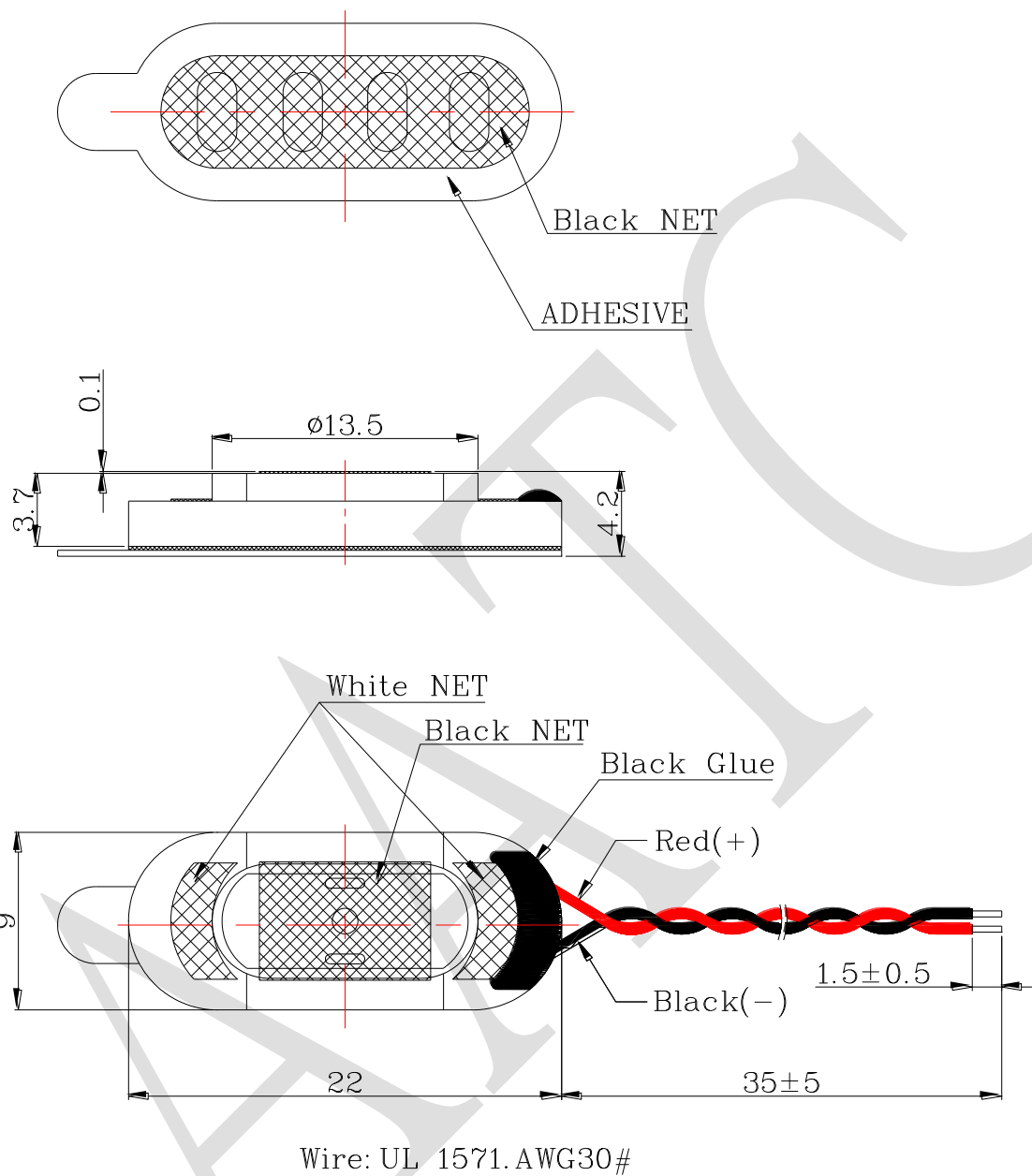

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2017/03/15	SCALE: 2:1	SHEET: 1:1
PART NO. AKV-22090810-PM-1W	1	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. ***-*****		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
	REV	MATERIAL: PBT	ONE PLACE DECIMAL $\pm$ ***		
			TWO PLACE DECIMAL $\pm$ ***		
			THREE PLACE DECIMAL $\pm$ ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKV-22090810-PM-1W](#)