


1. SPECIFICATION

AKV-20140808-PM-1WV

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 20 x 14 mm	
03	Rated Input Power	0.8 W	
04	Max. Input Power	1.0 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$ at 1 KHz 1V	
06	Resonance Frequency (Fo)	1000 Hz $\pm 20\%$ at Fo, 1V	
07	Sound pressure level	88 dB(0.8W/0.1M) ± 3 dB	at AVE 0.8, 1.0, 1.2, 1.5 KHz.
08	Frequency Range	Fo – 10 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.1W	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

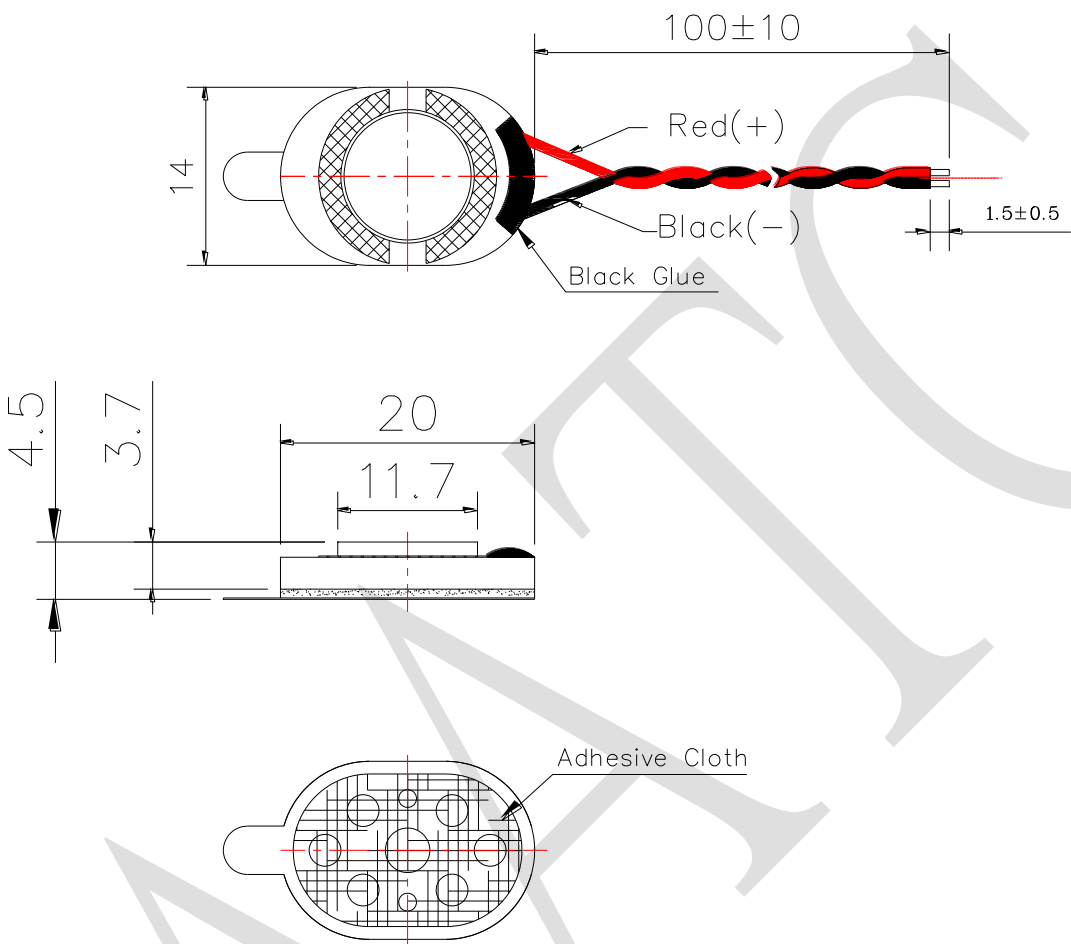

Wire: UL1571,AWG30#

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2017/10/25	SCALE: 2:1	SHEET: 1:1
PART NO. AKV-20140808-PM-1WV		DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. CXS2014045L100-R08W0.8-F		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: PBT		ONE PLACE DECIMAL ± ***	
	2			TWO PLACE DECIMAL ± ***	
	REV			THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKV-20140808-PM-1WV](#)