

1. SPECIFICATION

AK-M28M8-3C


ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 28 mm	
03	Rated Input Power	0.5 W	
04	Max. Input Power	1.0 W for 1 Minute.	
05	Impedance	8 ohm ± 15% at 1K Hz	
06	Resonance Frequency (Fo)	750 Hz ± 20% at Fo, 1V	
07	Sensitivity (S.P.L.)	90dB(0.1W/0.1m) ± 3 dB	at AVE 0.8,1.0,1.2,1.5 KHz.
		96 dB(0.5W/0.1m) ± 3 dB	
08	Frequency Range	Fo – 10K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz,0.1W.	

REV NO.

REVISION NOTE

APPROVAL

DATE

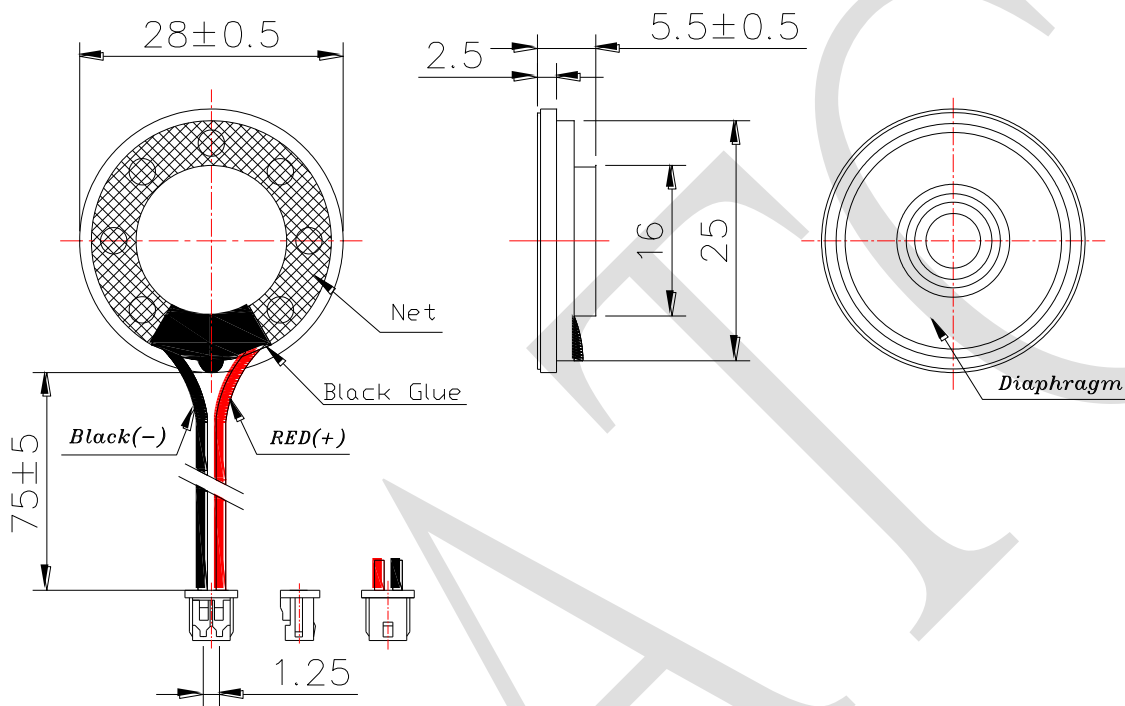

WIRE: UL1571,AWG28#

CONNECTOR:Equivalent to Molex 51021-0200

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Moose 2015/08/07

SCALE: 2:1

SHEET: 1:1

PART NO. AK-M28M8-3C

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. CXS28055LP75-R08W0.5-B1

2

APPROVAL:

UNLESS OTHERWISE SPECIFIED

ONE PLACE DECIMAL $\pm$ ***TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

REV

MATERIAL: SPCC



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AK-M28M8-3C](#)