


1. SPECIFICATION

AKB-30150810-PM-1C

ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Dimension	External diameter 30 x 15 mm	
03	Rated Input Power	1.0 W	
04	Max. Input Power	1.5 W for 1 minute	
05	Impedance	8Ω± 15% at 1KHz 1V	
06	Resonance Frequency (Fo)	900 Hz ± 20% at Fo, 1V	
07	Sound pressure level	90dB(1.0W/0.1M) ± 3 dB	at AVE 1.0, 1.2, 1.5, 1.8 KHz.
08	Frequency Range	Fo – 10 K Hz	
09	Total Harmonics Distortion	Max 10 % at 2 KHz, 1W	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

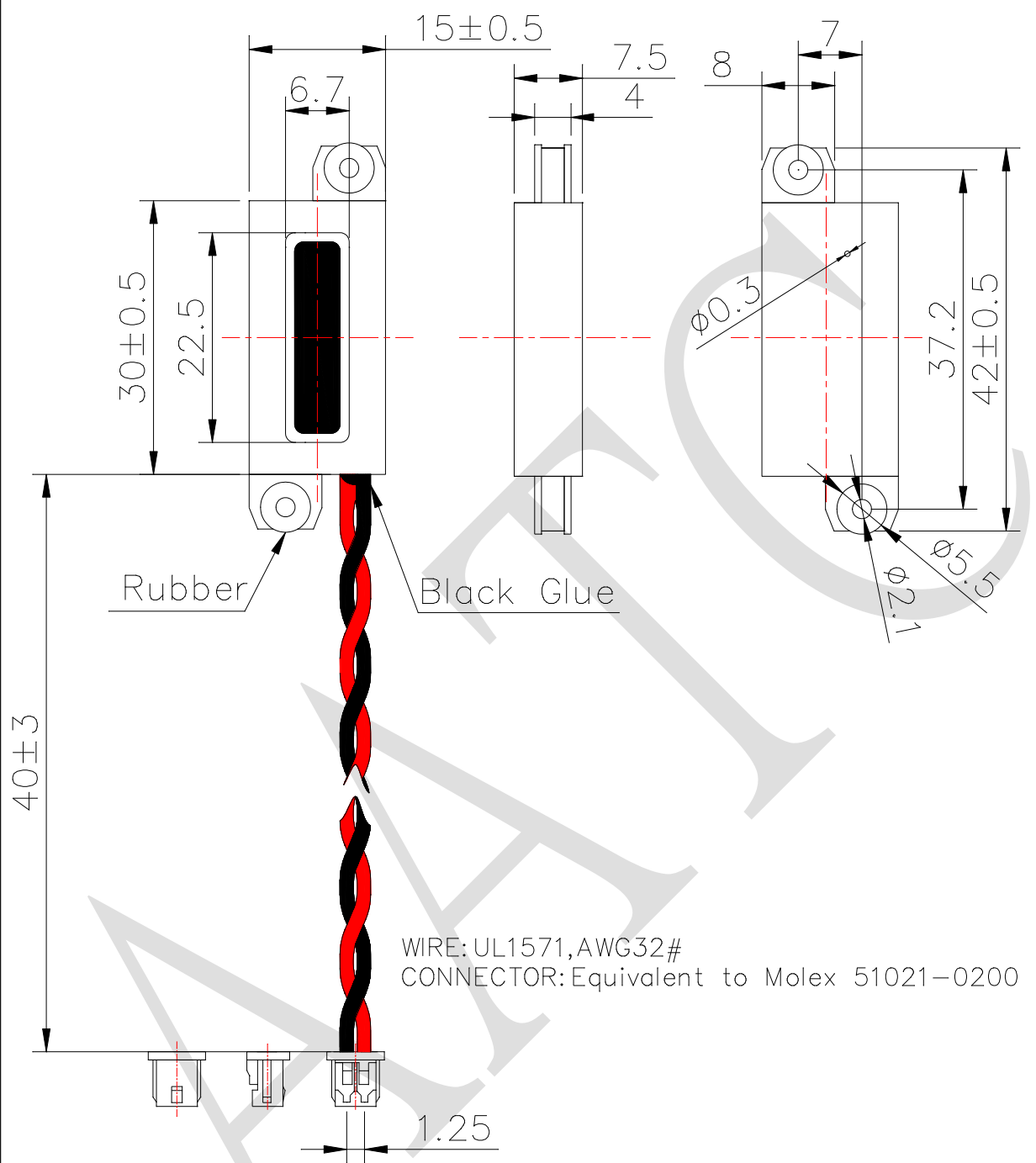

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Sunny 2017-6-26	SCALE: 1:1	SHEET: 1 : 1
PART NO. AKB-30150810-PM-1C	2	DESIGNED: R & D OF AAT	UNITS: mm	
DWG NO. JXS2509-BOX		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: ABS	ONE PLACE DECIMAL $\pm$ ***	
			TWO PLACE DECIMAL $\pm$ ***	
			THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKB-30150810-PM-1C](#)