

1. SPECIFICATION

AK-3208BB-2C (RoHS)


ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 32 mm	
03	Rated Input Power	2.0 W	
04	Max. Input Power	2.5 W for 1 minute	
05	Impedance	8Ω± 15% at 2.0KHz 1V	
06	Resonance Frequency (Fo)	550 Hz ± 20% at Fo, 1V	
07	Sensitivity (S.P.L.)	87 dB(0.1W/0.1M) ± 3 dB	at AVE 0.8, 1.0, 1.2, 1.5 KHz.
		100 dB(2.0W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 20 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.5V.	

REV NO.

REVISION NOTE

APPROVAL

DATE

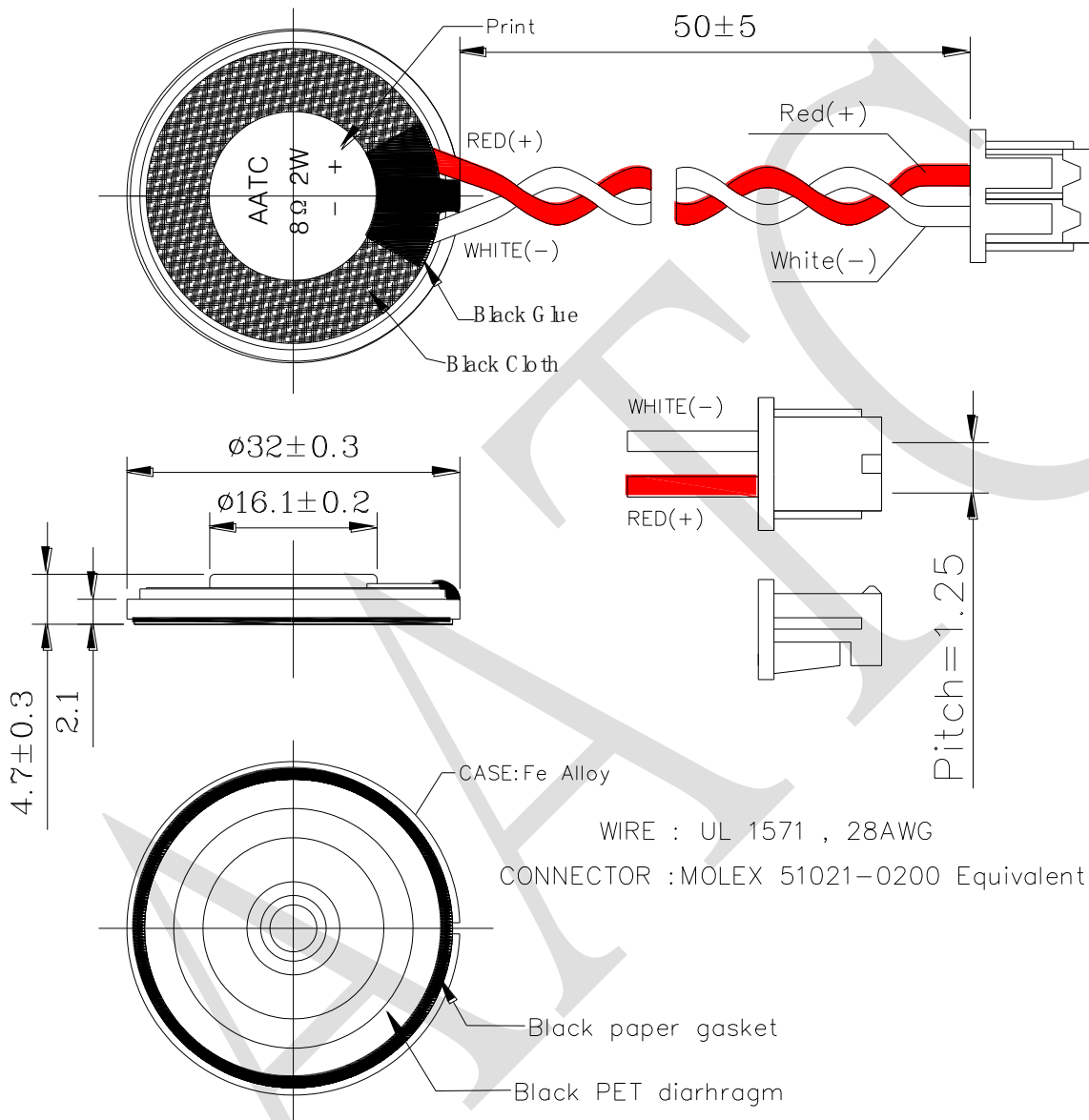

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Sunny

2012-10-31

SCALE: 2:1

SHEET: 1:1

PART NO. AK-3208BB-2C

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

DWG NO. CZ-100917

1

REV

MATERIAL: ALLOY

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AK-3208BB-2C](#)