


File Name:

AZ-4329S-FP

Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12	
02	Operating Voltage	VDC	4~28	
03	Rated Current	mA(Max)	8	At 12 VDC
04	Sound Output At 30 cm	dBA(Min)	78	At 12 VDC
05	Resonant Frequency	Hz	2900±500	
06	Tone Nature	SLOW PULSE (1.2Hz)		
07	Operating Temp.	℃	-30 ~ +85	
08	Storage Temp.	℃	-40 ~ +85	
09	Weight	g	32	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

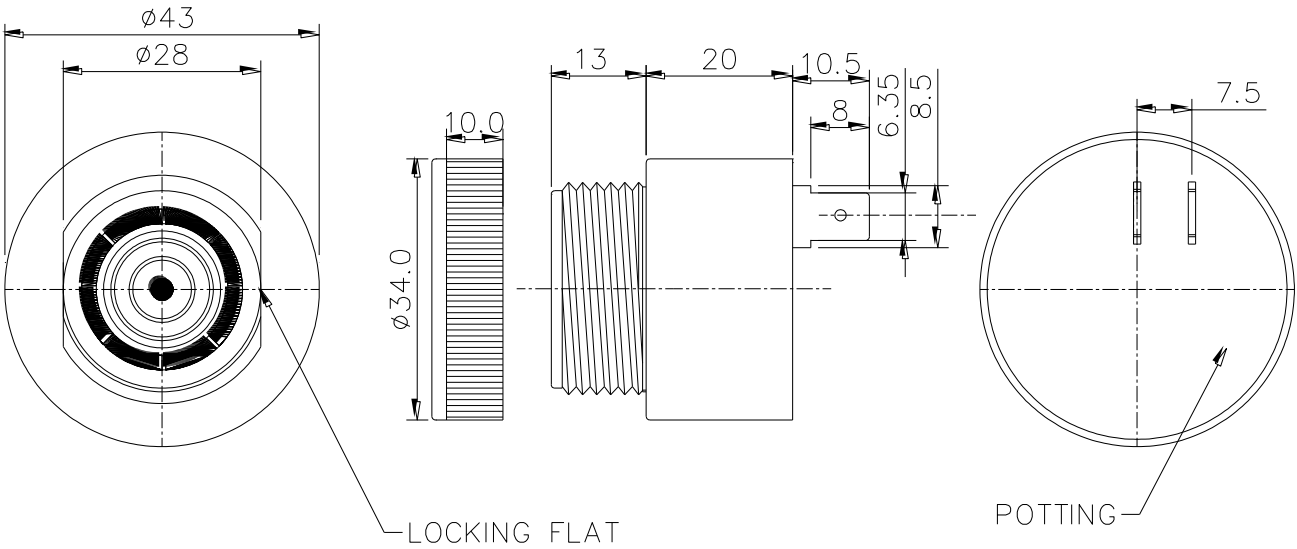

TITLE: <i>PIEZO BUZZER</i>		<div>1</div> <div>REV</div>	DRAWN: Milton 01/14/2002	SCALE: 1:1	SHEET: 1 of 1	
PART NO. <i>AZ-4329S-FP</i>			DESIGNED: <i>R & D OF AAT</i>	UNITS: <i>mm</i>	TOLERANCE $\pm 0.5\text{ mm}$ UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL \pm *** TWO PLACE DECIMAL \pm *** THREE PLACE DECIMAL \pm ***	
DWG NO. <i>DTP-1123</i>			CHECKED:			
			APPROVAL:			
			MATERIAL: <i>ABS</i>			



苙翔科技股份有限公司
 ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-4329S-FP](#)