

File Name:

AZ-4329S-P1(RoHS)


Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12	
02	Operating Voltage	VDC	6~28	
03	Rated Current	mA(Max)	12	At 12 VDC
04	Sound Output At 30 cm	dBA(Min)	95	At 12 VDC
05	Resonant Frequency	Hz	2900±500	
06	Tone Nature	Continuous		
07	Operating Temp.	℃	-20 ~ +60	
08	Storage Temp.	℃	-30 ~ +70	
09	Weight	g	36	

REV NO.

REVISION NOTE

APPROVAL

DATE

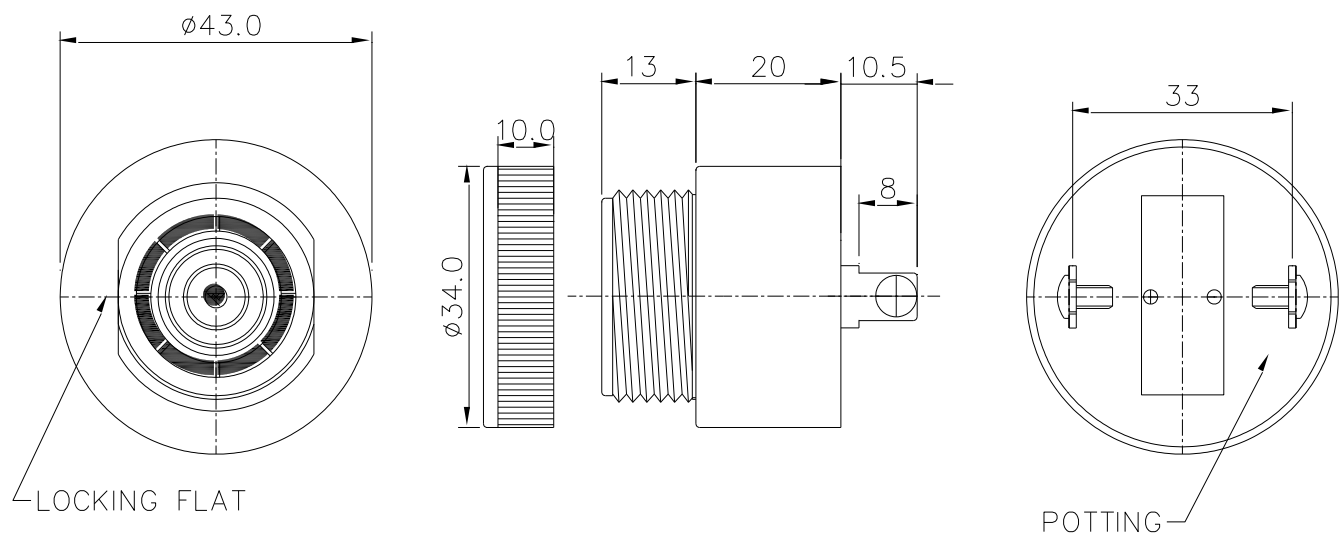

TITLE: PIEZO BUZZER

DRAWN: TOM

2008/07/09

SCALE: 1:1 SHEET: 1 of 1

PART NO. AZ-4329S-P1

DESIGNED: R &amp; D OF AAT

UNITS: mm

DWG NO. DTP-1189

CHECKED:

TOLERANCE  $\pm 0.5$  mm

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

MATERIAL: ABS



苙翔科技股份有限公司  
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-4329S-P1