


1. SPECIFICATION

AKB-80310825-PPC-3C1

ITEM		SPECIFICATIONS	
01	Type	Dynamic Speaker	
02	Dimension	External diameter 80 x 31.1 mm	
03	Rated Input Power	2.5 W	
04	Max. Input Power	3.0 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$ at 1.5KHz 1V	
06	Resonance Frequency (Fo)	700 Hz $\pm 20\%$ at Fo, 1V	
07	Sound pressure level	97 dB(2.5W/0.1M) ± 3 dB	at AVE 1.0, 1.2, 1.6, 2.0 KHz.
08	Frequency Range	Fo – 9 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.0W.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

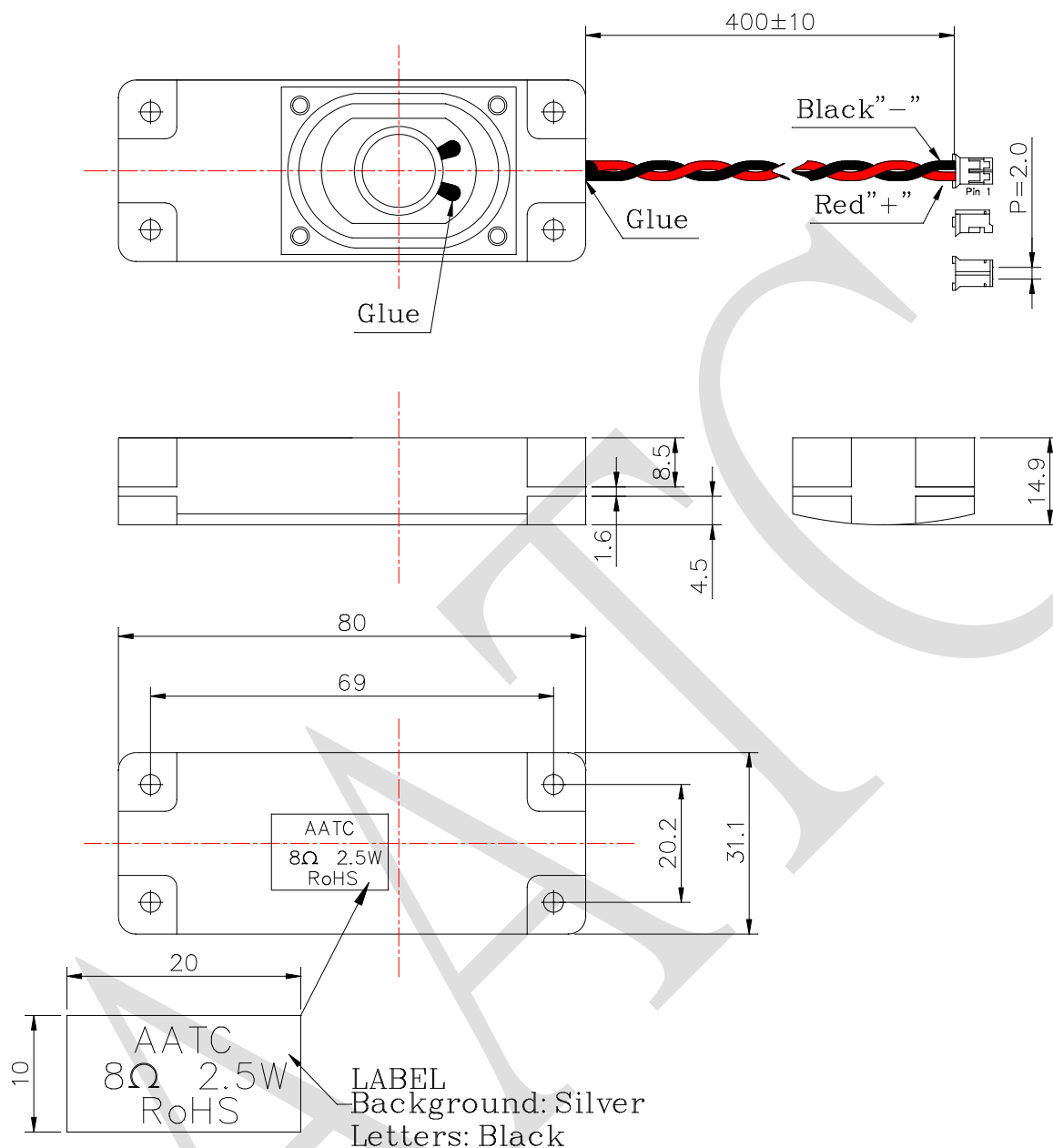

WIRE: UL1061,AWG 26.

CONNECTOR :Equivalent to JST PHR-2

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2017-12-6	SCALE: 2:1	SHEET: 1:1
PART NO. AKB-80310825-3C1	2	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. CA-K2017120601		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL ± *** TWO PLACE DECIMAL ± *** THREE PLACE DECIMAL ± ***		
	REV	MATERIAL: ABS			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AKB-80310825-PPC-3C1](#)