
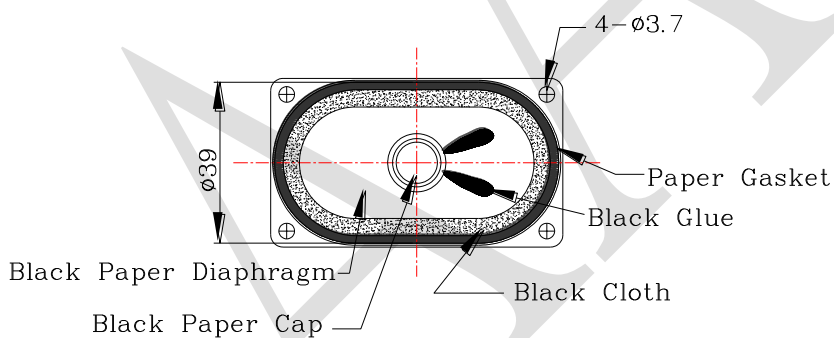


1. SPECIFICATION

AKR-714108C-C

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 71 x 41 mm	
03	Rated Input Power	4.0 W	
04	Max. Input Power	5.0 W for 1 minute	
05	Impedance	$8\Omega \pm 15\%$ at 0.8KHz 1V	
06	Resonance Frequency (Fo)	450 Hz $\pm 20\%$ at Fo, 1V	
07	Sound pressure level	80 dB(1.0W/0.5M) ± 3 dB	at AVE 0.8, 1.0, 1.2, 1.5 KHz.
		100 dB(4.0W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 20 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.5V.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

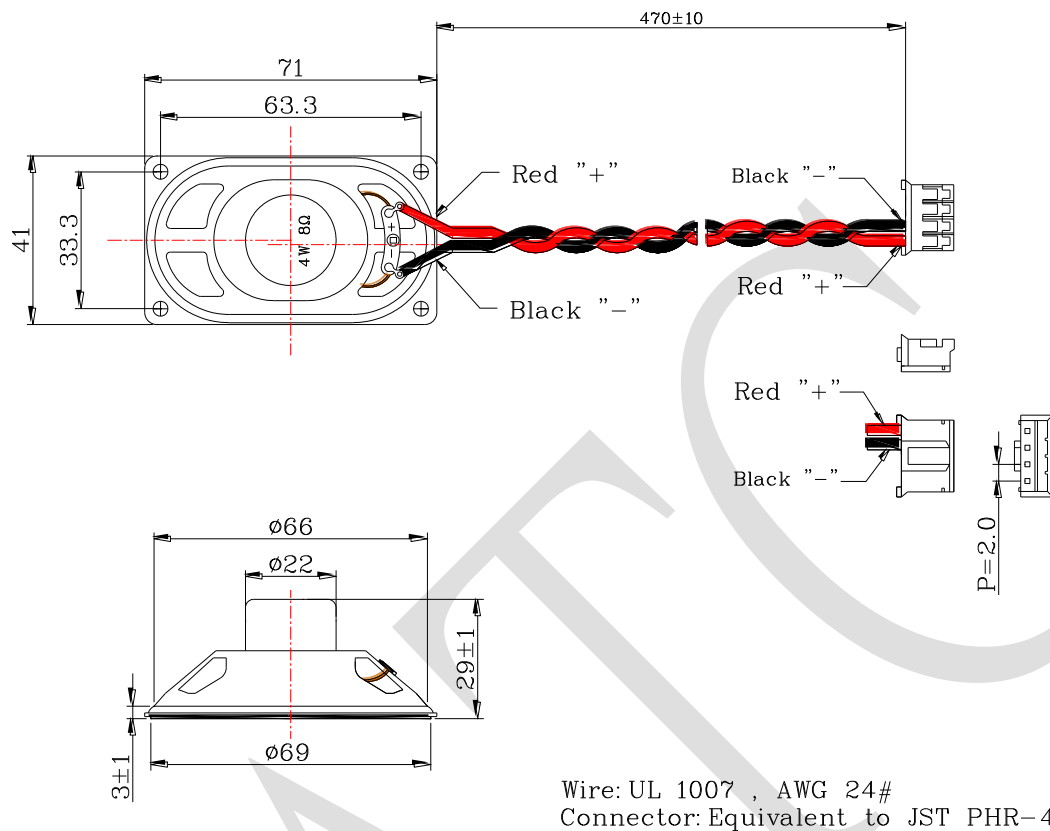

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Jerry	2012/11/30	SCALE: 2:1	SHEET: 1:1
PART NO. AKR-714108C-C	1 REV	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. TV-4171A-R+ WIRE		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL ± *** TWO PLACE DECIMAL ± *** THREE PLACE DECIMAL ± ***		
		MATERIAL: IRON			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

AATC

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AKR-714108C-C