

1. SPECIFICATION

AK-303203-PP-1W




ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 30 mm	
03	Rated Input Power	0.3 W	
04	Max. Input Power	0.5 W for 1 minute	
05	Impedance	$32\Omega \pm 15\%$ at 1KHz 1V	
06	Resonance Frequency (Fo)	250Hz $\pm$ 20% at Fo, 1V	
07	Sound pressure level	86 dB(0.3W/0.1M) $\pm$ 3 dB	at AVE 0.4,0.6 0.8, 1.0 KHz.
08	Frequency Range	Fo – 10 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.1 W.	

REV NO.

REVISION NOTE

APPROVAL

DATE

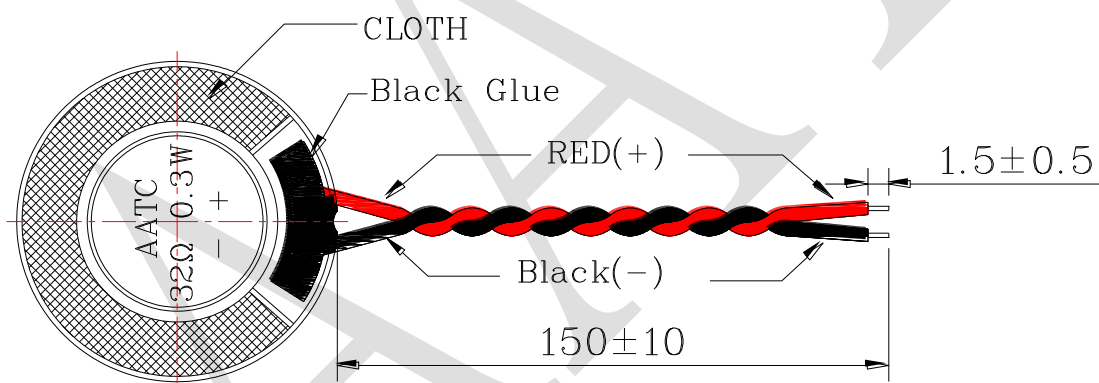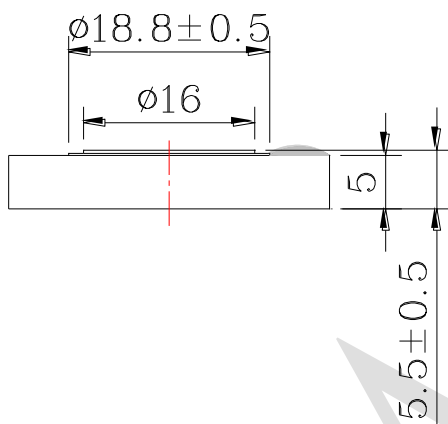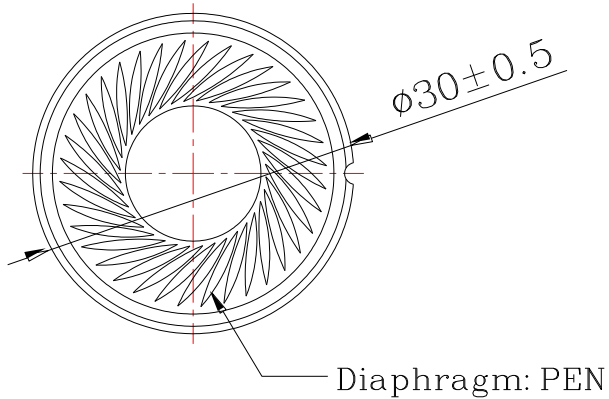

WIRE: UL 1007. AWG26#

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Moose

2018/04/16

SCALE: 2:1

SHEET: 1:1

PART NO.
AK-303203-PP-1W

1

DESIGNED: R&D OF AAT

CHECKED:

APPROVAL:

DWG NO.
CXS30050L150-R32W0.3-H

REV

MATERIAL: ABS

UNITS: mm

TOLERANCE ± 0.5

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-303203-PP-1W](#)