


1. SPECIFICATION

AK-770820-MP-1

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 77 mm	
03	Rated Input Power	2.0 W	
04	Max. Input Power	3.0 W for 1 minute	
05	Impedance	8Ω ± 15% at 0.8 KHz 1V	
06	Resonance Frequency (Fo)	340 Hz ± 20% at Fo, 1V	
07	Sensitivity (S.P.L.)	98 dB(2.0W/0.5M) ± 3 dB	at AVE 0.3, 0.5, 0.6, 0.8 KHz.
		110 dB(2.0W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 2 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.0W	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

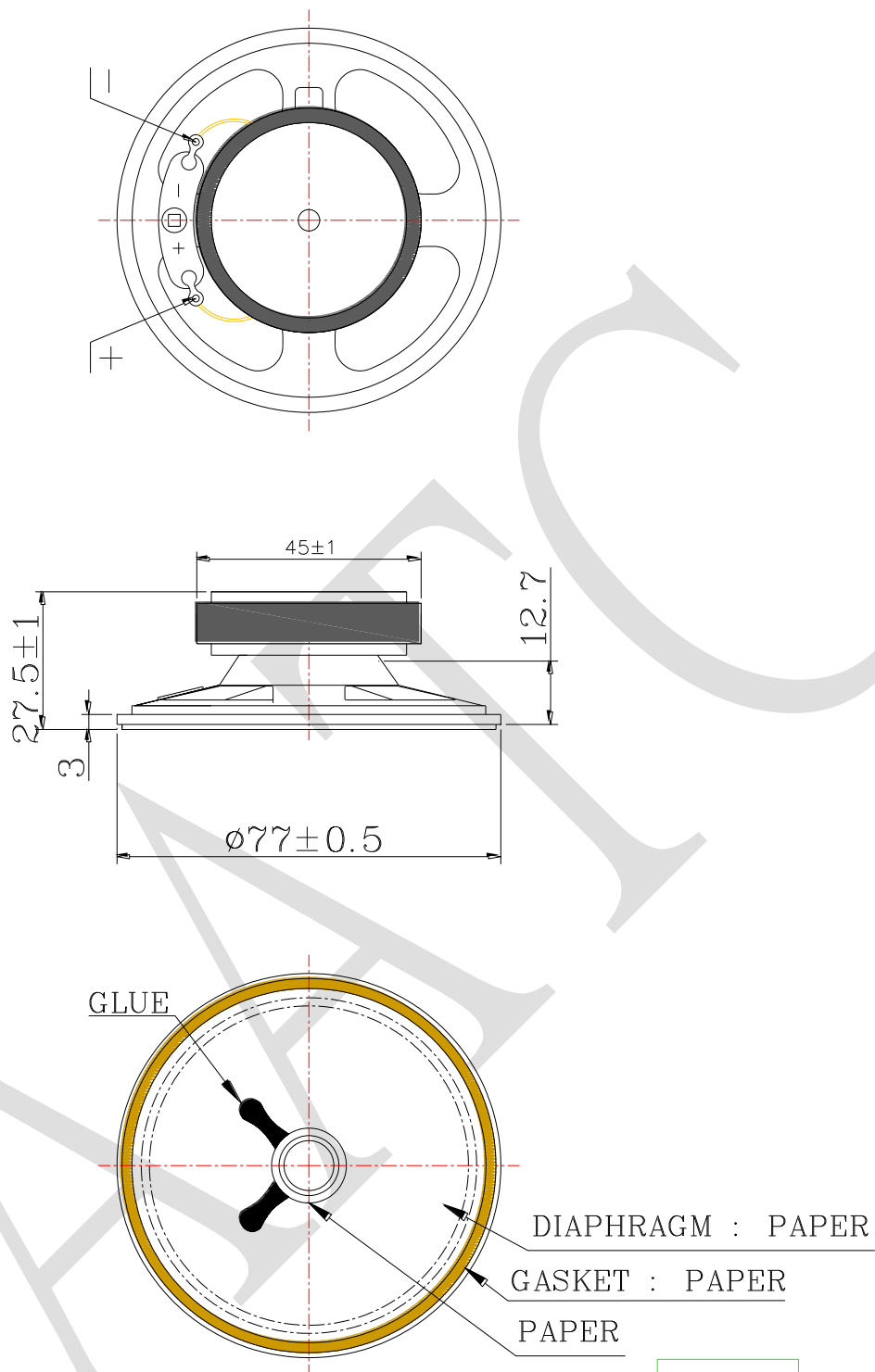

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2016/09/12	SCALE: 2:1	SHEET: 1:1
PART NO. AK-770820-MP-1		DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. TR-077F-R(105090601)		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: ALLOY		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-770820-MP-1](#)