


1. SPECIFICATION

AE-B2065E-1C

TYPE		EXTERNAL -drive type sound element		
ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Input Voltage	V (Max)	30	Vp-p (Square Wave) 1/2 duty
02	Resonant Frequency	KHz	6.5± 0.5	at 25± 2℃ , 45~60% RH
03	Resonant Impedance	Ω (Max)	500	at 25± 2℃ , 45~60% RH
04	Capacitance	pF	14000±30%	At 120Hz
05	Plate Material			BRASS

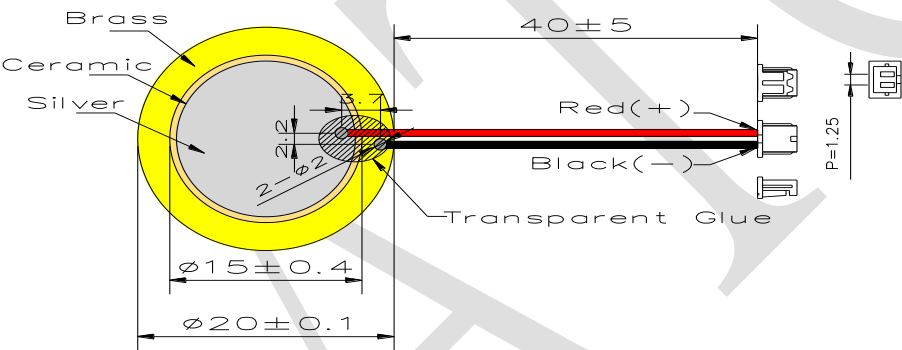

UNIT:MM
TOLERANCE: ± 0.5
WIRE:UL1571,AWG30#
CONNECTOR:Equivalent to MOLEX 51021-0200

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AE-B2065E-1C](#)