


1. SPECIFICATION

AK-787808GF-1 (RoHS)

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 78X78 mm	
03	Rated Input Power	5.0 W	
04	Max. Input Power	10 W for 1 minute	
05	Impedance	8Ω ± 15% at 800 Hz 1V	
06	Resonance Frequency (Fo)	180 Hz ± 40Hz at Fo, 1V	
07	Sensitivity (S.P.L.)	90 dB(1.0W/0.5M) ± 3 dB	at AVE 0.8, 1.0, 1.2, 1.5 KHz.
		96 dB(5.0W/0.5M) ± 3 dB	
08	Frequency Range	Fo – 3.5K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.5V.	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

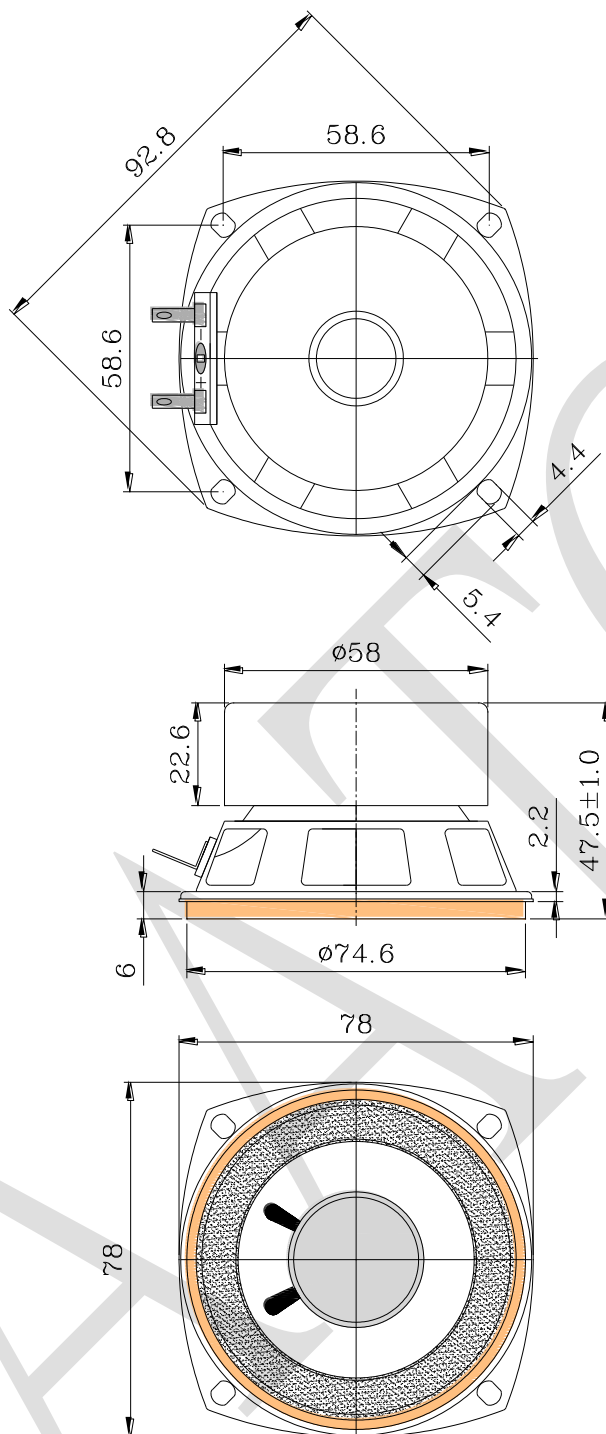

RoHS

TITLE: DYNAMIC SPEAKER		DRAWN: Zack	2015/06/12	SCALE: 2:1	SHEET: 1:1
PART NO. AK-787808CF-1	2	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. TQ-077FMA-R		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: ALLOY		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-787808GF-1](#)