

1. SPECIFICATION

AK-3608BB-34




ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 36 mm	
03	Rated Input Power	0.5 W	
04	Max. Input Power	0.8 W for 1 minute	
05	Impedance	8Ω ± 15% at 1.5KHz 1V	
06	Resonance Frequency (Fo)	550 Hz ± 20% at Fo, 1V	
07	Sensitivity (S.P.L.)	92 dB(0.1W/0.1M) ± 3 dB	at AVE 0.6, 0.8, 1.0, 1.2 KHz.
		98 dB(0.5W/0.1M) ± 3 dB	
08	Frequency Range	Fo – 5 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 1.5V.	

REV NO.

REVISION NOTE

APPROVAL

DATE

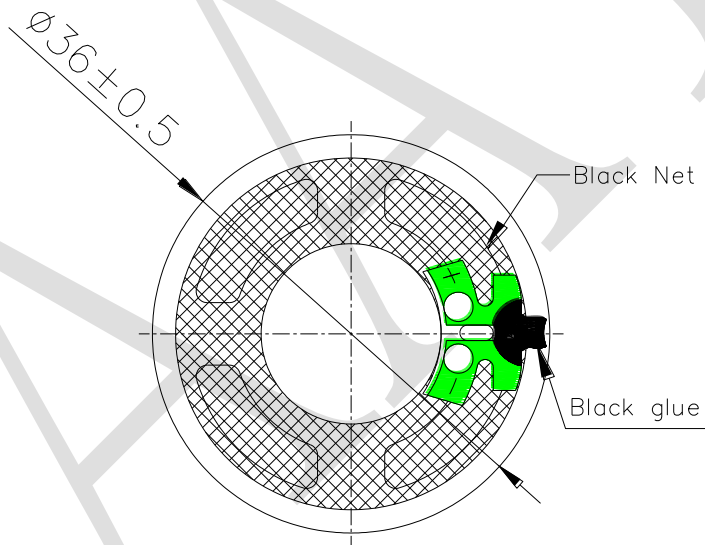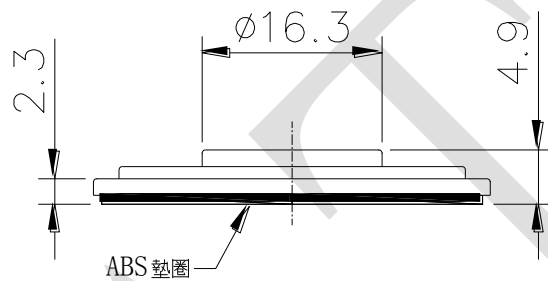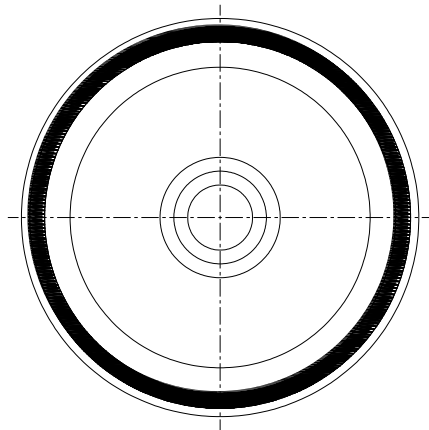

RoHS

TITLE: DYNAMIC SPEAKER

DRAWN: Zack 2014/11/13

SCALE: 2:1

SHEET: 1:1

PART NO. AK-3608BB-34

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. UGS3608-07

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: ALLOY+PET

ONE PLACE DECIMAL $\pm$ ***TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AK-3608BB-34](#)