
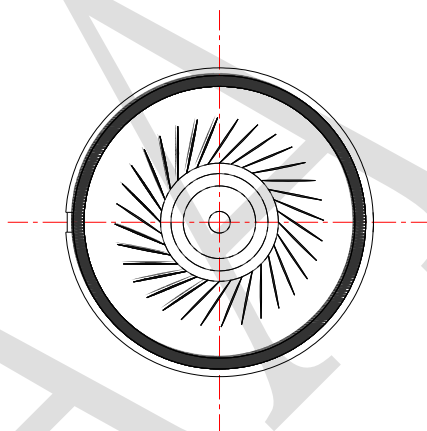
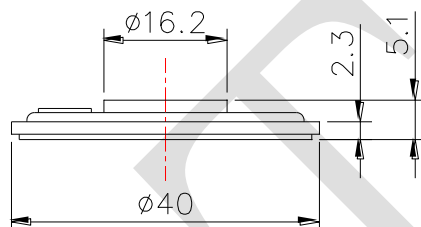


1. SPECIFICATION

AK-4004BB-2-LF

ITEM		SPECIFICATIONS	
01	Type	Dynamic speaker	
02	Dimension	External diameter 40 mm	
03	Rated Input Power	1.0 W	
04	Max. Input Power	1.5 W for 1 minute	
05	Impedance	4 Ω ± 15% at 2 KHz 1V	
06	Resonance Frequency (Fo)	600 Hz ± 20% at Fo, 1V	
07	Sound pressure level	100 dB(1.0W/0.1M) ± 3 dB	at AVE 0.8, 1.0, 1.2, 1.6 KHz.
08	Frequency Range	Fo – 6 K Hz	
09	Total Harmonics Distortion	Max 10 % at 1 KHz, 0.1W	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

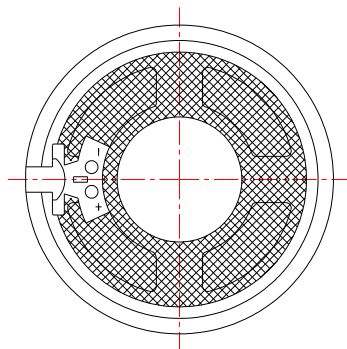

RoHS

TITLE: DYNAMIC SPEAKER		2	DRAWN: Zack	2015/03/05	SCALE: 2:1	SHEET: 1:1
PART NO.	AK-4004BB-2-LF		DESIGNED: R&D OF AAT	UNITS: mm		
			CHECKED:	TOLERANCE ± 0.5		
DWG NO.	UGS4004-04-01		REV	APPROVAL:	UNLESS OTHERWISE SPECIFIED	
			MATERIAL: SPCC	ONE PLACE DECIMAL ± ***		
				TWO PLACE DECIMAL ± ***		
				THREE PLACE DECIMAL ± ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AK-4004BB-2-LF](#)