


1. SPECIFICATION

SD-153B

	ITEM	UNIT	SPECIFICATIONS	CONDITION
01	Dimension 尺寸	mm	Φ 28 X 7.4	Refer to attached drawing in details.
02	Input power 輸入功率	mW	50	White noise is applied for 96 hours.
03	Max. Input power 額定輸入最大功率	mW	Max. 100	at room temperature for 60s on and 120s off for 10 cycles.
04	Impedance 交流阻抗	Ω	150 ±20%	at 1KHz /1V.
05	S.P.L 音壓位準 Sound pressure level	dB	93 ±3	at 1KHz 60mV with IEC318 coupler.
06	Frequency range 有效頻寬	Hz	300~4K	
07	T.H.D 總諧波失真 Total Harmonics Distortion	%	Max. 10	at 1KHz ,1 m W.

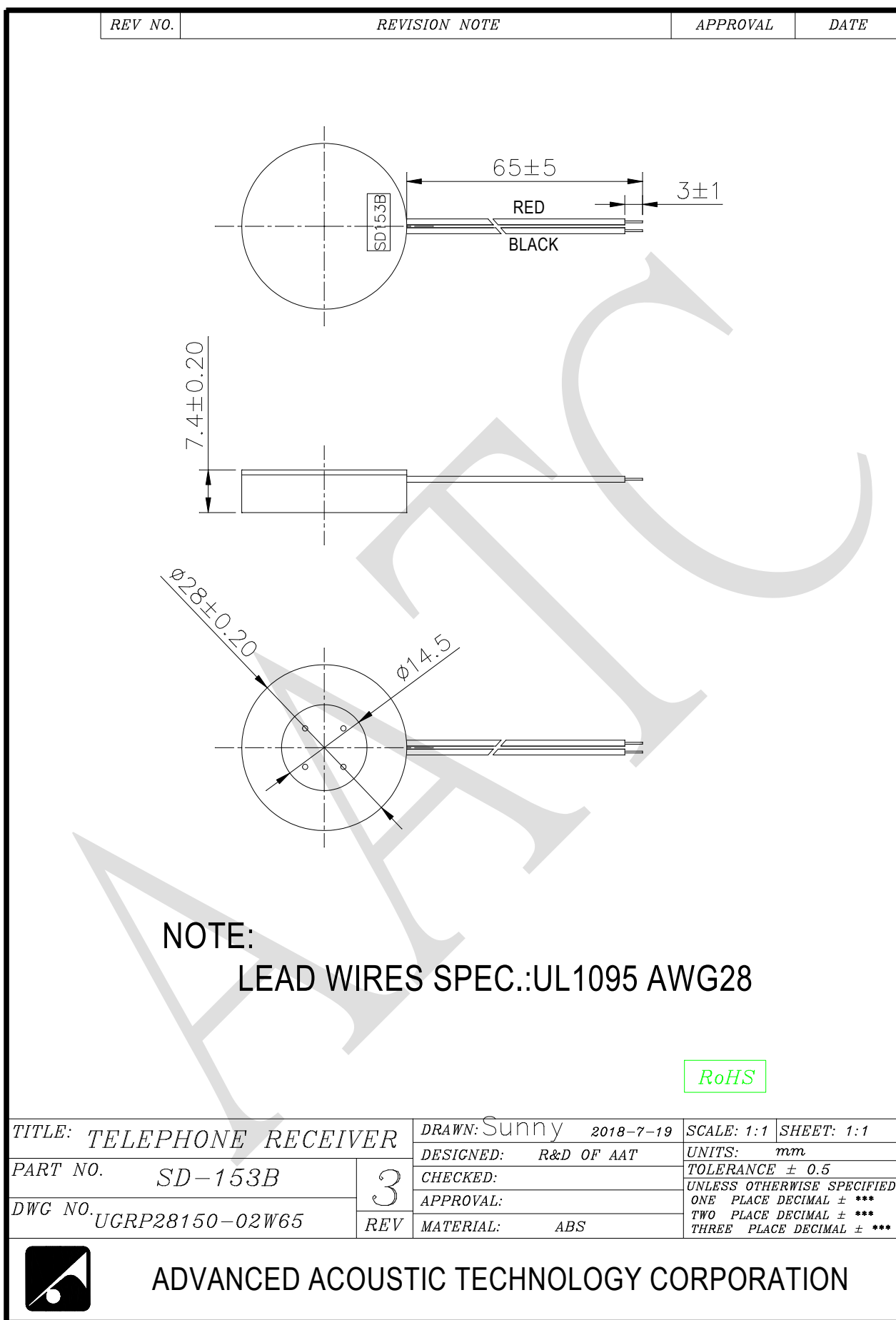

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)
[SD-153B](#)